

MECHANICAL DETAILS

Shell Style Model EG* : Fixed receptacle nut fixing


Keying 1 key (alpha=0, plug: male contacts, receptacle: female contacts)

Housing Material Brass (chrome plated) shell and collet nut, nickel plated brass latch sleeve and mid pieces

Cable Fixing 0 - 0 mm

Variant 2 :

	B	L	M	N	S1	S3
Mm.	10.3	15.5	1	13.7	6.3	9
In.	0.41	0.61	0.04	0.54	0.25	0.35

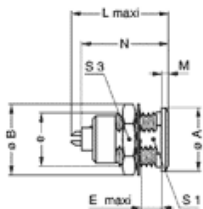

Available Download

 [unipole_multipole.pdf](#)

PERFORMANCE DETAIL

Insert :

Insulator L: PEEK

Specifications

Contact Type: Solder

Max. Matings: 5000

Contact Dia.: 0.35 mm (0.01in)

Bucket Dia.: 0.4 mm (0.016in)

Max. Solid 0.09 mm² (AWG 28)

Max. Stranded 0.05 mm² (AWG 30)

R (max): 8.7 mOhm









OTHER CHARACTERISTICS

Shell Style/Model Libellé

IP Rating 50



Related links

-  [Contact](#)
-  [Quote Request](#)
-  [Catalogs Downloads](#)
-  [Catalogs Requests](#)
-  [Sample Request](#)
-  [3D drawings](#)