

rotronic

Datenblatt - Fiche technique - Data sheet


11.99.8949




VALUE USB 2.0 Kabel, Typ A-A, ST/BU, 1,8m

VALUE Câble USB 2.0 Type A-A, M/F, 1,8m

VALUE USB 2.0 Cable, Type A-A, M/F, 1.8 m

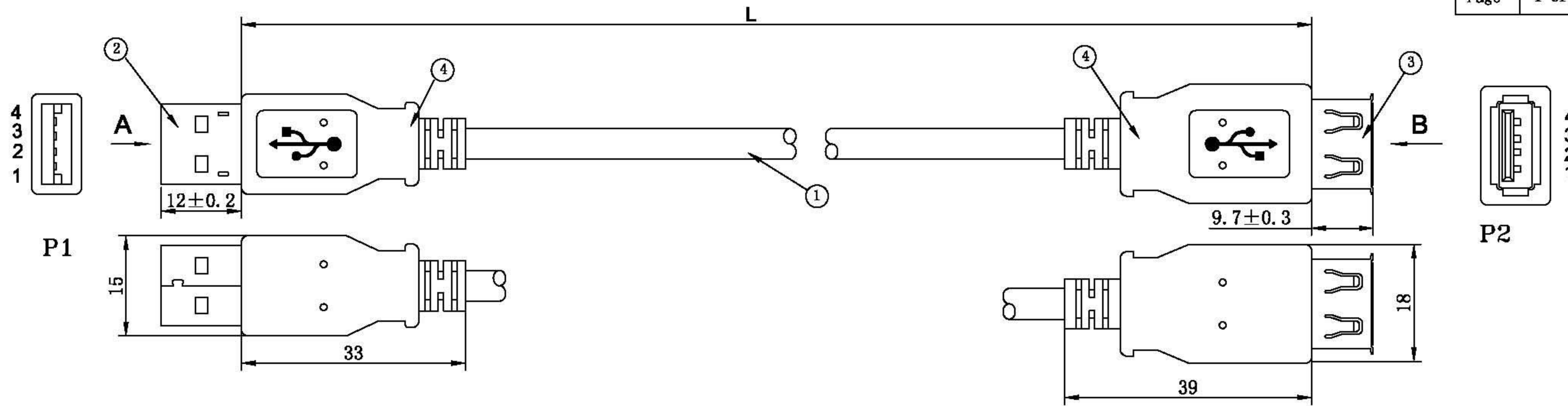

PIN OUT

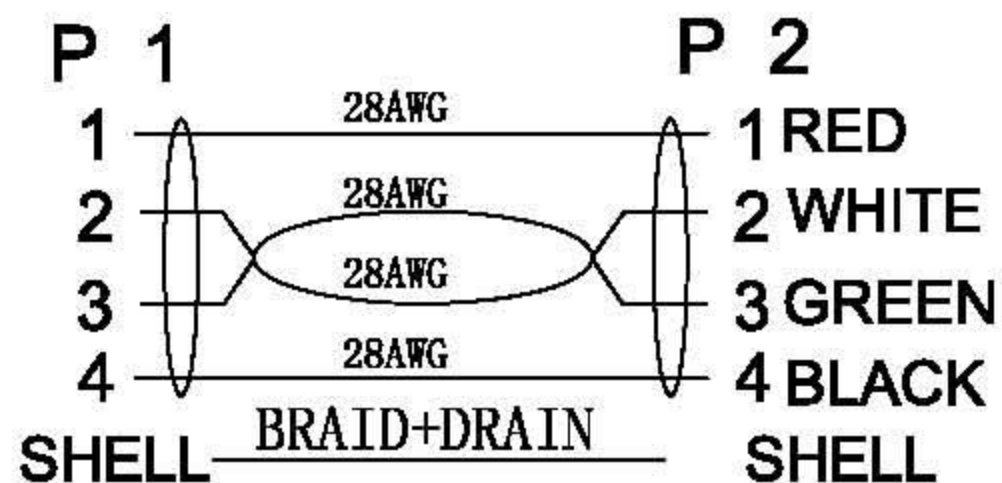

NOTE 1:

ITEM NO.	LENGTH
11.99.8946R	800±20mm
11.99.8949R	1800±30mm
11.99.8961R	3000±50mm

NOTE:

1. Electrical test:
 - (1). 100% open short & miss wire test;
 - (2). Insulation resistance: DC 300V 10M Ω;
 - (3). Contactor resistance: 5Ω Max;
 - (4). Dielectric strength: 100V AC/Minute, 1mA.
2. RoHS compliant
3. PRINTING: USB 2.0 CABLE, 28AWG×1P+28AWG×2C
4. Packing: 1PCS/PE BAG + LABEL 100PCS/CARTON

MATERIAL LIST:

④	OUTER MOLD	Shore 88A PVC(UL94V-2)color For White	2	
③	USB A TYPE	USB A /F Type, The Pin Gold Plating 30u", the shell for Nickel Plating	1	
②	USB A TYPE	USB A /M Type, The Pin Gold Plating 30u", the shell for Nickel Plating	1	
①	CABLE	USB 2.0 28AWG(7/0.12BC*1P)+28AWG(7/0.12BC*2C)+AEB B=0.12/3*16 AL-MG E=7/0.12BC JACKET:PVC/WHITE (WH11) OD: 3.8±0.2mm	1	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK

Rotonic Co., Ltd

		REF.	ITEM NO.	11.99.8946	11.99.8961
				11.99.8949	
PRODUCT NAME		USB 2.0 AM/AF		DRAW NO.	UNTT
DRAWNBY		CHECKBY		APPOBY	
ALVAN		ALVAN		DATE	
BY		CHK		REVISION RECORD MODIFICATIONS	
		DATE	REV.	2009-11-20	
			A	2009-11-20	