

M12 B-coded 4-poles, male straight connector

M12 B-coded 4-poles, female straight connector


*For Information Only  
won't be replaced when changed*

length in "1m" step	40	XXX=400
	39	XXX=390
	.	.
	12	XXX=120
	11	XXX=110
length in "0,1m" step	10	XXX=100
	9,9	XXX=099
	9,8	XXX=098
	.	.
	0,4	XXX=004
	0,3	XXX=003
	0,2	XXX=002
	0,1	XXX=001
Step	a [m]	XXX

4,0 to 40	+1%
0,1 to 3,9	+0,04
a [m]	Tolerance

Part no.	213488894XXXXX
----------	----------------

Type of cable	XX
PVC violett, 2xAWG22	XX=86
PE violett, 2xAWG24	XX=87

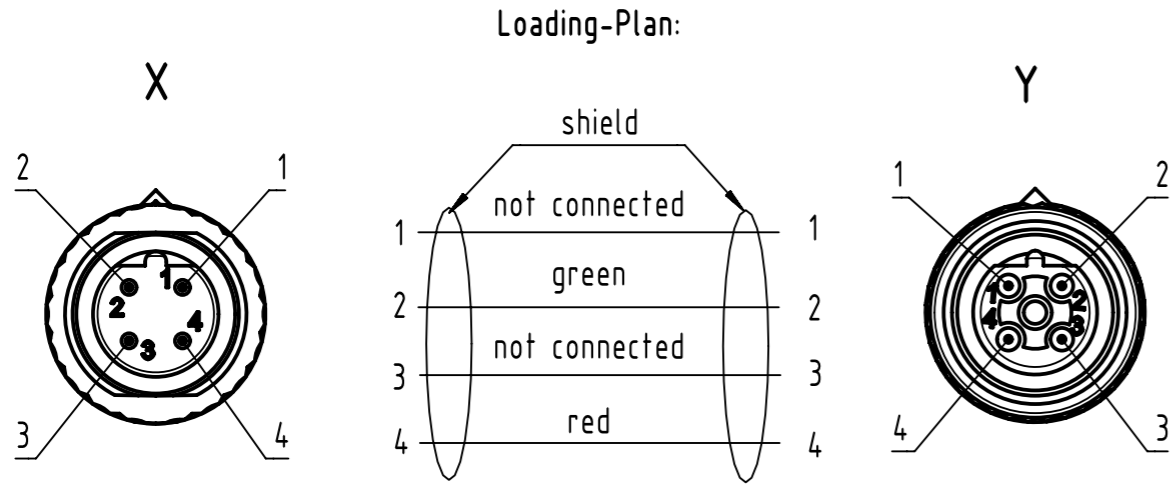

- Protection level: IP67  
- Temperature range: -30°C ... +60°C

All rights reserved Department EC PD - RO HARTING Electronics GmbH D-32339 Espelkamp		All Dimensions in mm Original Size DIN A3 Scale 2:1 Free size tol.	Ref. Sub.	Created by TOMUTA Inspected by Standardisation Date 2014-05-29 State Checked Out	Title M12 B-coded Cable Assembly Type TB Number 213488894XXXXX	Doc-Key / ECM-Nr. 100579391/UGD/009/A Rev. A Page 1/1
---	--	---	--------------	--	--	--