


A B C D E F G H

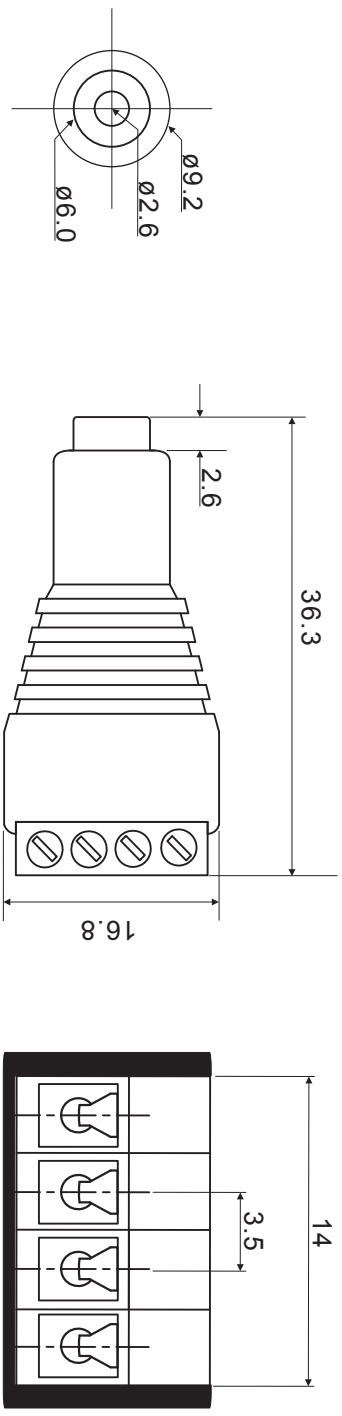


Technical Data:


Electrical:

- Voltage rating: 12VDC
- Current rating: 5A
- Contact resistance: <20mΩ
- Insulation resistance: 500MΩ / DC500V
- Wire range: 24-18AWG

Mechanical:

- Torque: 0.2Nm (1.8lb/in)
- Operating temperature: -40°C to 105°C
- Strip length: 4.5-5mm

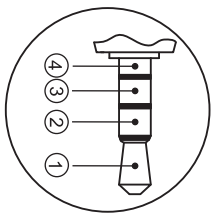

DATE	REVISION	APPROVAL BY	DIMENSION	mm ±0.3	MODEL No	CLB-JL-8129
			DRAW BY	Camilly Pun	NAME	4 Conductor 2.5mm Female Jack Adaptor
			APPROVAL BY	RIKIKI So	 Concept Design Manufacture	
			DATE	01-05-2015	c.ie-group Ltd 3 Widdowson Close, Blenheim Ind Est Bilwell, Nottingham NG5 8WB, England T: +44(0)115 9770075 F: +44(0)115 9770881 E: info@c.ie-group.com W: www.c.ie-group.com	

1 2 3 4 5 6