
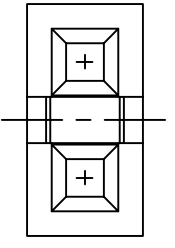
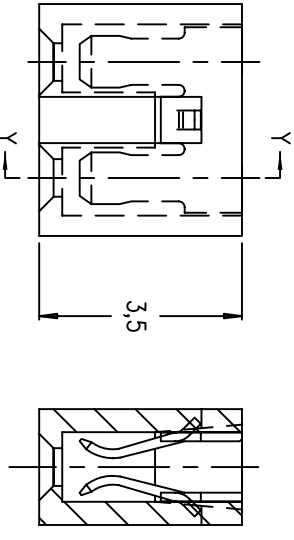


PRODUCT NO	PLASTIC MAT'L	COLOR	TERMINAL MAT'L	TERMINAL PLATING
86730-001	PBT	BLACK	PHOSPHOR BRONZE	0,2um MIN Au OVERPLATE
-101	PBT	BLACK	PHOSPHOR BRONZE	0,762um MIN Au OVERPLATE
-301	PBT	BLACK	PHOSPHOR BRONZE	0,381um MIN Au OVERPLATE
-401	PBT	BLACK	PHOSPHOR BRONZE	3,81um MIN SnPb OVERPLATE
-002	PBT	BLUE	PHOSPHOR BRONZE	0,2um MIN Au OVERPLATE
-102	PBT	BLUE	PHOSPHOR BRONZE	0,762um MIN Au OVERPLATE
-302	PBT	BLUE	PHOSPHOR BRONZE	0,381um MIN Au OVERPLATE
-402	PBT	BLUE	PHOSPHOR BRONZE	3,81um MIN SnPb OVERPLATE

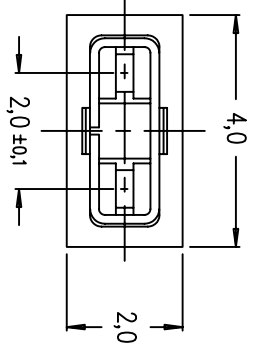

- NOTES
- HOUSING MAT'L IS PER UL 94V-0
 - PRODUCT TO BE MATED WITH 0.5 mm SQ PIN.
 - PRODUCT DESCRIPTION CODE :
XXXXX-XXXXLF
LEAD FREE (4)
EXTENSION NUMBER
BASE NUMBER

- 86730-XXXXLF IS SAME AS 86730-XXX. THE SUFFIX 'LF' IS ADDED JUST FOR EASY LEAD FREE IDENTIFICATION
- THE HOUSING WILL WITHSTAND EXPOSURE TO 200° C PEAK TEMPERATURE FOR 10 SECONDS IN A CONVECTION, INFRA-RED OR VAPOR PHASE REFLOW OVEN.
- THIS PRODUCT MEETS EUROPEAN UNION DIRECTIVES AND OTHER COUNTRY REGULATIONS AS DESCRIBED IN GS-22-008.

CONFIDENTIAL

product family
MINITEK

title
MINITEK JUMPER

itr	ecn no	dr	date	surface	tolerance	projection
K	S04-0271	KBM	12/21/04	ISO 1302	ISO 406 ISO 1101	MM
L	S06-0236	KHL	7/17/06	ISO 1302	ISO 406 ISO 1101	MM
H	SS00056	BSL	3/23/95	ISO 1302	ISO 406 ISO 1101	MM
J	S04-0045	JPEH	3/19/04	ISO 1302	ISO 406 ISO 1101	MM

sheet no	86730	sheet 1 of 1	size	A
type	Product Customer Drawing			