


NOTE:

- Display port 1.4 Mode
- Input: Display port Male TX
- Output: Display port Male RX
- Plug and Play
- Connector the pin and shell gold plating
- Metal housing with lock
- Converts electrical data signals to optical signals
- 4core OM3 Multimode Fiber (high speed data)and 7core copper cable
- Round cable Black TPU jacket
- Easy to install with Active Optic Cable
- Supports bandwidth up to 32.4Gbps
- Resolution: 4K@120HZ (4:4:4) 8bit
- Resolution: 8K@60HZ (4:4:4) 8bit
- Supports 3D/HDCP2.2/EDID/HDR
- ROHS2.0 and REACH compliant

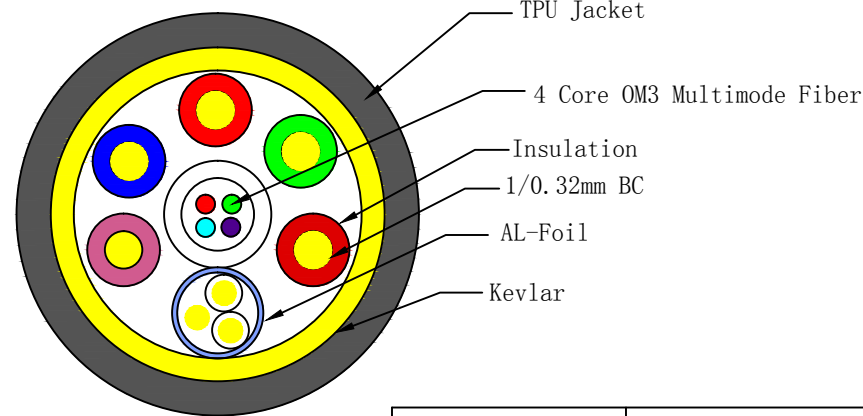

Item no	Length
14.01.3490	30000mm ^{+500mm} _{-100mm}
14.01.3492	50000mm ^{+500mm} _{-100mm}

DESC.	ROLINE Display Port 1.4 Male-Male Hybrid active optical cable (AOC) metal plug with lock
-------	--

		NEW	2019-5-20	A
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.

SECOMP