

 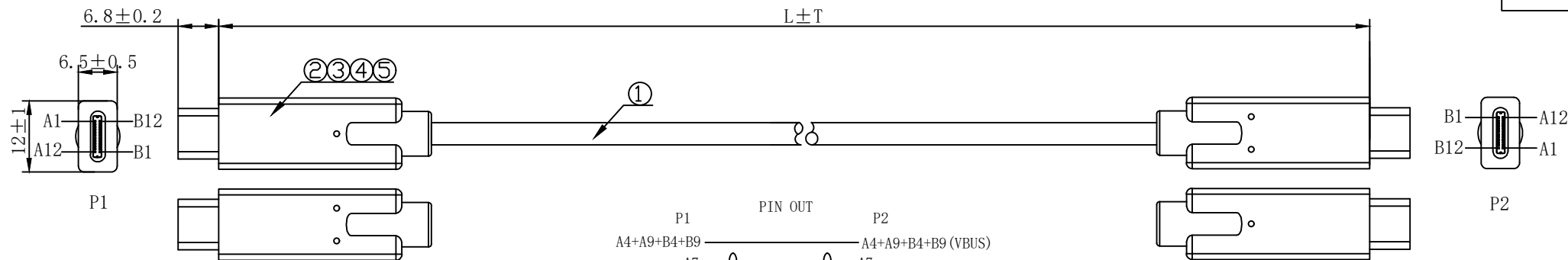
 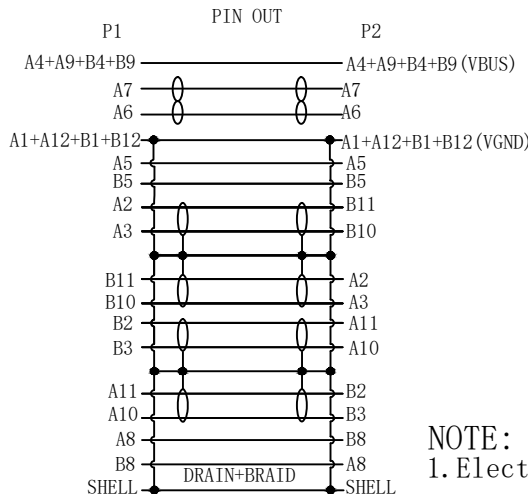


UNIT	MM
------	----



USB4 Type C Male

USB4 Type C Male



ITEM NO.	Length (mm)
11.02.9091	500 ± 20
11.02.9092	800 ± 30
11.02.9082	1000 ± 20

NOTE:

1. Electrical test:

- (1). 100% open short & miss wire test;
- (2). Insulation resistance: DC 100V 0.01S 5M ohm;
- (3). Contactor resistance: 3 ohm Max;
- (4). SSD TEST: 1800MB/S (min)

2. Feature:

Full-featured USB4 Type-C Cable (USB4 Gen3x2)
 Transmission rate Up to 40Gbps
 Resolution up to single 8k@60Hz with DSC or dual 4k@60Hz
 Backwards compatible with USB 3.2, 3.1 and 2.0 and Thunderbolt 3
 Supports USB power delivery 3.0 (EPR 5-20V 5A) 100W

3. RoHS 2.0 and REACH Compliant

MATERIAL LIST:

⑤	OUT MOLD	TPE MOUDDLING	2	
④	INNER MOLD	LD-PE	2	
③	E-mark	USB4 GEN3*2 40Gbps 100W/5A MAX	1	
②	TYPE C	USB4 C/M SOLDER TYPE, BLACK PBT INSULATION, THE PIN GOLD PLATING, THE SHELL FOR NICKEL PLATING+IRON SHIELD	2	
①	CABLE	USB4 GEN3*2 [32AWG*1P+D+AM+HM]*4C+32AWG*1P+32AWG*4C+24AWGBC*2C+D+AM+B TPE JACKET BLACK OD:4.5±0.15MM	1	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK

		Add new lengths	2023-03-13	A1
		NEW	2022-06-23	A
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.

ROLINE USB4 Gen3x2 (40Gbit/s)Cable, CM-CM, 100W,black
Product description

SECOMP