


7069157 & 7069169

3026

3025

RETORT BASES

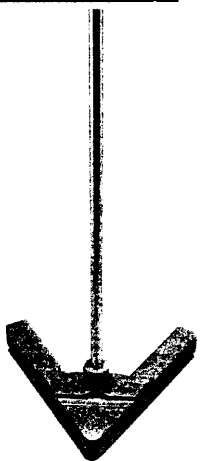

3025

SPREAD BASES

Manufactured in cast iron and painted acrylic blue, with central rod hole tapped 10 mm fitted with rubber feet.

ROD CENTRE/ FOOT CENTRE	WEIGHT
3025/1 70 mm	0.65 Kg
3025/2 100 mm	1.25 Kg
3052/3 135 mm	1.55 Kg
3052/4 175 mm	2.5 Kg

- 3025/1
- 3025/2
- 3052/3
- 3052/4


3026

A SHAPE

Manufactured in cast iron, resting on 3 feet. Clear rod hole 13 mm diameter to accept 3109 series rods with plastic headed screw, painted acrylic blue. Dimensions: Leg length 200 mm, Width between legs 160 mm, Weight: 2.5 Kg

3019

3019/1

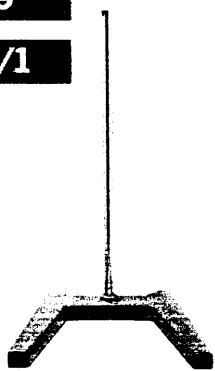

3026/1

A SHAPE

As number 3026 but with tapped hole to accept 3108 series rods.

3019

H SHAPE

Manufactured in cast iron and painted acrylic blue for use with stirrers etc. For use with 18 mm diameter nickel plated steel rod 700 mm length - 3019/1. Other lengths can be supplied on request. Dimensions: Leg length 270 mm, Front Opening: 245 mm, Weight: 5.5 Kg.

