

[Home](#) |
[Contact Us](#) |
[Where to Buy](#) |
[Site Search](#) | **Choose a Solution or Product category, then press Go**



All Products

Automotive Products

Basic Electrical Testers

Cable Testers

Calibrators

Clamp Meters

Comm. Test Tools

Data Acquisition

Digital Multimeters

Gas Measurement

Network Products

Power Supplies

Oscilloscopes

RCL Meters

Process Products

Power Quality Tools

ScopeMeters

Thermometers


Signal Sources

Timer/Counters

TV Generators

Fluke T5 Voltage, Continuity and Current Testers

[Product Home](#) | [Specifications](#) | [Models, Options & Accessories](#)

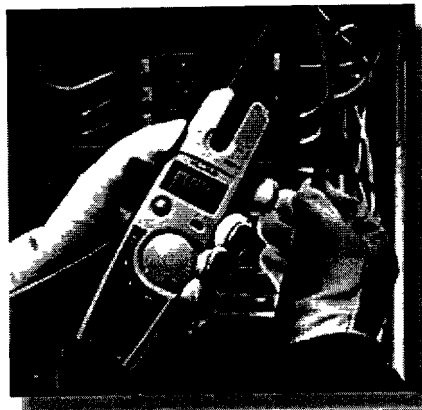

Electrical tester with OpenJaw™ Current

The Fluke T5 Electrical Testers let you check voltage, continuity and current with one compact tool. With the T5, all you have to do is select volts, ohms, or current and the tester does the rest. OpenJaw™ current lets you check current up to 100A - without breaking the circuit. Its tough test leads stow neatly in the back of the tester, making it easy to tote the T5 in your tool pouch. Detachable SlimReach™ test probes are customized for national electrical standards. The test leads accept optional accessories such as clips and specialty probes. The optional H5 holster lets you clip the T5 onto your belt. Available in 600V and 1000V models.

Features at a glance:

- Automatically measures volts ac and volts dc with precise digital resolution
- Displays resistance to 1000Ω
- Easy and accurate OpenJaw™ current measurement
- Continuity beeper
- Compact design with neat probe storage
- Rugged enough to withstand a 10-foot (3m) drop
- Detachable SlimReach™ probe tips are customized for national electrical standards
- Test leads accept Fluke accessory test clips
- Available in 600V and 1000V models
- Can stay connected much longer than solenoid type tester
- Auto off mode to conserve battery life
- Optional holster attaches to a belt and neatly stows test leads

[Home](#) |
 |

[Contact Us](#) |

[Where to Buy](#) |

[Site Search](#) |
 Choose a Solution or Product category, then press Go



- All Products**
- Automotive Products
- Basic Electrical Testers
- Cable Testers
- Calibrators
- Clamp Meters
- Comm. Test Tools
- Data Acquisition
- Digital Multimeters
- Gas Measurement
- Network Products
- Power Supplies
- Oscilloscopes
- RCL Meters
- Process Products
- Power Quality Tools
- ScopeMeters
- Thermometers
- Signal Sources
- Timer/Counters
- TV Generators

Fluke T5 Voltage, Continuity and Current Testers Specifications

[Product Home](#) | [Specifications](#) | [Models, Options & Accessories](#)

- [General Specifications](#)

General Specifications	
Battery	<p>Type: Two AA zinc chloride</p> <p>Life: 200 hour zinc chloride, 400 hour alkaline; low battery indicator</p>
Test leads	<p>Type: Heavy duty, flexible leads rated for 1000V use. Field replaceable leads terminate in male shrouded banana plugs</p> <p>Probes: One red, one black. Detachable Slim-ReachT probe tips in one of two tip</p> <p>Styles: TP1 flat blade (US style) or TP4 4 mm round (European style)</p>
Continuity beeper	<p>Threshold: On at <25Ω, off at >400Ω</p>
Volts indicator LED	<p>Threshold: Guaranteed on by 30V ac</p>
Environmental	<p>Operating temperature: -10°C to 50°C</p> <p>Storage temperature: -30°C to 60°C</p> <p>Temperature coefficient: 0.1 x (specified accuracy)/degree C (<18°C or >28°C)</p> <p>Relative humidity: 0% to 95% (5°C to 30°C) 0% to 75% (30°C to 40°C) 0% to 45% (40°C to 50°C)</p> <p>Operating altitude: 2000 meters max Dust and water resistant</p>
Mechanical	<p>Size: 30.5 mm H x 51 mm W x 203 mm L (1.2" x 2.0 8.0") approximate</p>

	Weight: 0.3 kg (10 oz) approximate Current sensor opening: 12.9 mm (.508")
Safety	Maximum operating voltage: T5-600: 600V ac/dc, Overvoltage Category III T5-1000: 1000V ac/dc, Overvoltage Category III between any terminal and earth ground Agency approvals: UL, CSA, and VDE
General	Warranty: 2 years Calibration cycle: 1 year

© 1995 - 2000 Fluke Corporation
Privacy Statement

- [Home](#)
- [Contact Us](#)
- [Where to Buy](#)
- [Site Search](#)

Find Solutions For:

All



Choose a Solution or Product category, then press Go

- All Products**
- [Automotive Products](#)
- [Basic Electrical Testers](#)
- [Cable Testers](#)
- [Callipers](#)
- [Clamp Meters](#)
- [Comm. Test Tools](#)
- [Data Acquisition](#)
- [Digital Multimeters](#)
- [Gas Measurement](#)
- [Network Products](#)
- [Power Supplies](#)
- [Oscilloscopes](#)
- [RCL Meters](#)
- [Process Products](#)
- [Power Quality Tools](#)
- [Scope Meters](#)
- [Thermometers](#)
- [Signal Sources](#)
- [Timer/Counters](#)
- [TV Generators](#)

Fluke T5 Voltage, Continuity and Current Testers Models, Options & Accessories

[Product Home](#) | [Specifications](#) | [Models, Options & Accessories](#)

Model Name	Product Description
T5-1000 *	1000V Voltage, Continuity and Current Tester
T5-600 *	600V Voltage, Continuity and Current Tester

*Includes instruction sheet and probe tips

Available Accessories and Options

Model Name	Accessory or Option Description
AC85A	Large Jaw Alligator Clips
C520	Leather Tester Case
H5	Custom Holster
TP1	Slim Reach™ Test Probe
TP2	Slim Reach™ Test Probe
TP4	Slim Reach™ Test Probe

© 1995 - 2000 Fluke Corporation
[Privacy Statement](#)