

WIRE DISPENSER



- With 50ft. (15.2m) Roll of 30 AWG (0.25mm) KYNAR® wire-wrapping wire.
- Built-in Plunger cuts wire to desired length.
- Built-in Stripper strips 1" (25.4mm) of insulation.
- Refillable.

PART No.	DESCRIPTION
WD-30-B	Blue Wire Dispenser
WD-30-Y	Yellow Wire Dispenser
WD-30-W	White Wire Dispenser
WD-30-R	Red Wire Dispenser

ROLLS OF WIRE



Wire for wire wrapping. 30 AWG (0.25mm) KYNAR® wire, 50ft. (15.2m) roll, silver plated, solid conductor, easy stripping.

PART No.	DESCRIPTION
R-30B-0050	30 AWG (0.25mm) Blue 50ft. (15.2m) roll
R-30Y-0050	30 AWG (0.25mm) Yellow 50ft. (15.2m) roll
R-30W-0050	30 AWG (0.25mm) White 50ft. (15.2m) roll
R-30R-0050	30 AWG (0.25mm) Red 50ft. (15.2m) roll


TRI-COLOUR DISPENSER



- 3 Rolls of Wire in one dispenser.
- 3 Colours: Blue, White, Red, 50ft. (15.2m) of each colour.
- 30 AWG (0.25mm) KYNAR® insulated Wire.
- Built-in Plunger cuts wire to desired length.
- Built-in Stripper strips 1" (25.4mm) of insulation.
- Refillable.

PART No.	DESCRIPTION
WD-30-TRI	Dispenser

TRI-COLOUR DISPENSER REPLACEMENT ROLLS

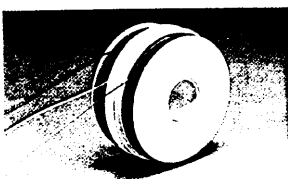


- 30 AWG (0.25mm) KYNAR® insulated Wire.
- 3 Colours: Blue, White, Red, 50ft. (15.2m) of each colour.
- Silver plated, solid conductor, easy stripping.

PART No.	DESCRIPTION
R-30-TRI	Replacement tri-colour rolls

REPLACEMENT STRIPPING BLADES

PART No.	DESCRIPTION
RSB-24	For 24AWG (0.5mm)
RSB-30	For 30AWG (0.25mm)

SOCKET-WRAP I.D. INCREASE WIRING SPEED AND REDUCE ERRORS

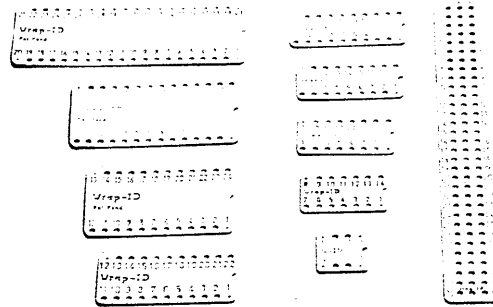

Used to identify pin numbers on wire wrapping sockets. Consisting of a socket-sized plastic panel with numbered holes in the pin location, the Socket Wrap-ID is simply slipped onto the socket before wrapping. You can also write on them for easy identification of location, IC part number, function, etc. These unique items greatly simplify both initial wire-wrapping and subsequent trouble-shooting or repair. A great help to technicians, and production facilities alike.

PART No.	ROW PINS	DESCRIPTION SPACING	QTY/PKG
ID-8-100	8	0.3" (7.5mm)	100
ID-14-100	14	0.3" (7.5mm)	100
ID-16-100	16	0.3" (7.5mm)	100
ID-18-50	18	0.3" (7.5mm)	50
ID-20-50	20	0.3" (7.5mm)	50
ID-22-50	22	0.3" (7.5mm)	50
ID-24-50	24	0.6" (15mm)	50
ID-28-25	28	0.6" (15mm)	25
ID-40-25	40	0.6" (15mm)	25
ID-96-25	96	0.3" (7.5mm)	25

**KYNAR AND
TEFZEL WIRE IS
AVAILABLE ON
100M, 500M AND
BULK SPOOL
LENGTHS.
TWISTED PAIR WIRE
IS ALSO AVAILABLE
ON REQUEST.
PLEASE CONTACT
SALES OFFICE**