


List Numbers and Dimensions

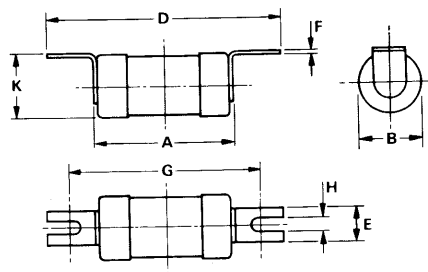



2-20A rating Extended Motor Range 20M25 & 20M32†

Rating	List Numbers
Amp	For ordering purposes
2	NIT 2
4	NIT 4
6	NIT 6
10	NIT 10
16	NIT 16
20	NIT 20
20M25	NIT 20M25†
20M32	NIT 20M32†

Dimensions in millimetres & inches

	A	B	D	E	F	G	H	K
	Fixing Centres							
mm	36.50	13.90	55.60	11.10	0.80	44.50	4.70	14.30
inches	1 ⁷ / ₁₆	3 ⁵ / ₆₄	2 ³ / ₁₆	7 ¹ / ₁₆	1 ¹ / ₃₂	1 ³ / ₄	3 ³ / ₁₆	9 ¹ / ₁₆

BS88: 1975 Dimensional Ref. **A1**

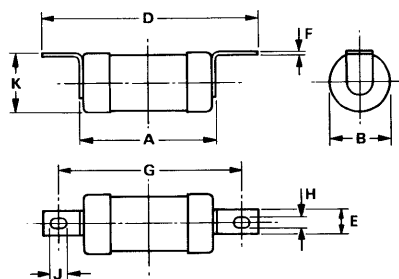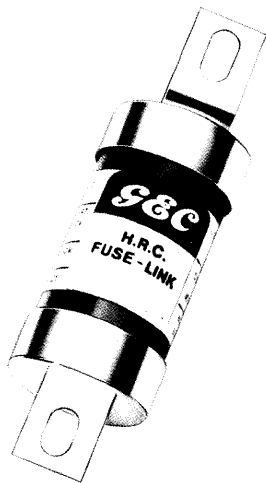

2-32A rating Extended Motor Range 32M35-32M63†


Rating	List Numbers
Amp	For ordering purposes
2	TIA 2
4	TIA 4
6	TIA 6
10	TIA 10
16	TIA 16
20	TIA 20
25	TIA 25
32	TIA 32
32M35	TIA 32M35†
32M40	TIA 32M40†
32M50	TIA 32M50†
32M63	TIA 32M63†

Dimensions in millimetres & inches


	A	B	D	E	F	G	H	J	K
	Fixing Centres								
mm	56.40	23.80	85.80	8.70	1.20	73.00	5.20	7.10	23.80
inches	2 ⁷ / ₃₂	1 ⁵ / ₁₆	3 ³ / ₈	1 ¹ / ₃₂	3 ³ / ₆₄	2 ⁷ / ₈	1 ³ / ₆₄	9 ¹ / ₃₂	1 ⁵ / ₁₆

BS88: 1975 Dimensional Ref. **A2**

Time/Current Characteristics

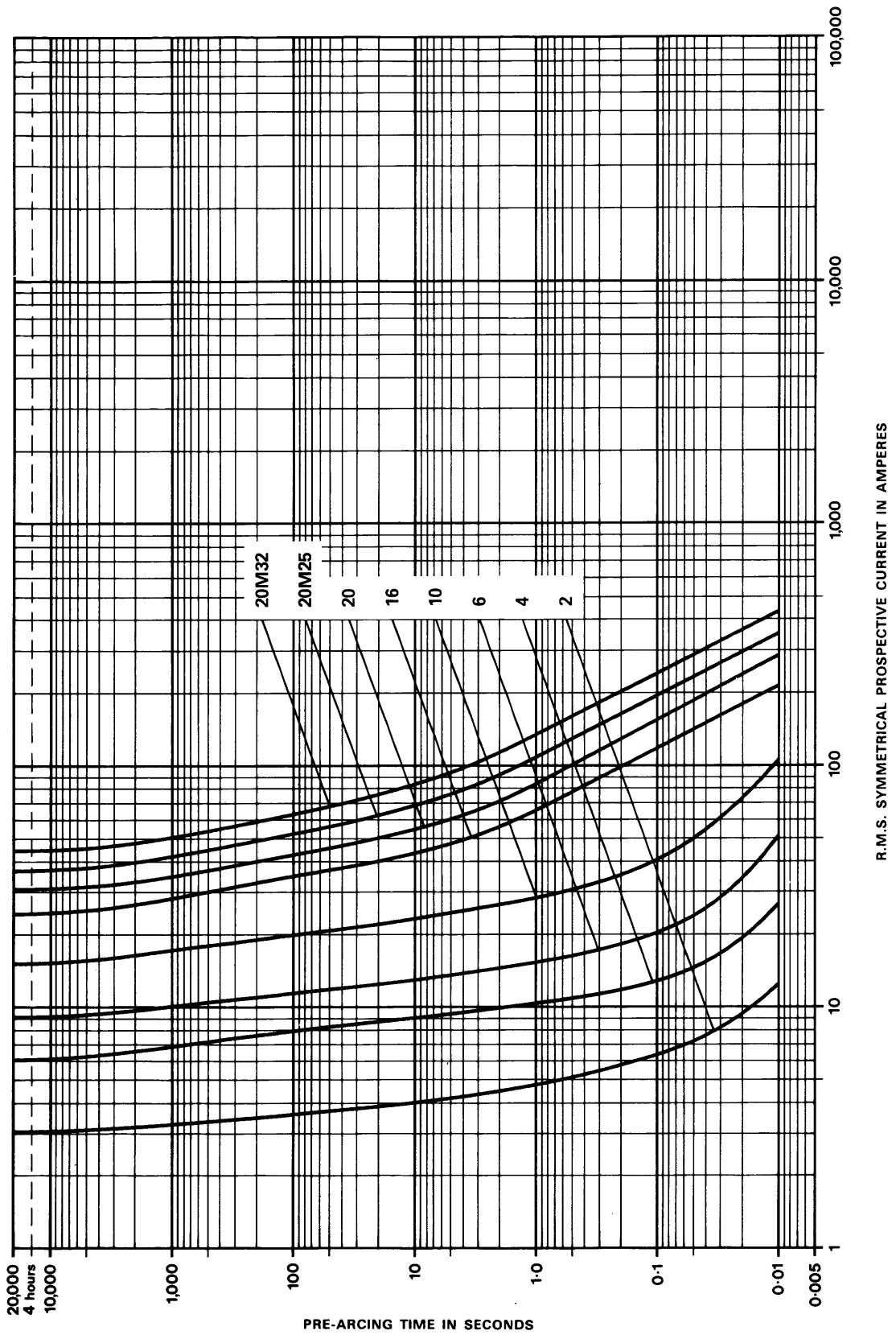

Cut-off Current Characteristics

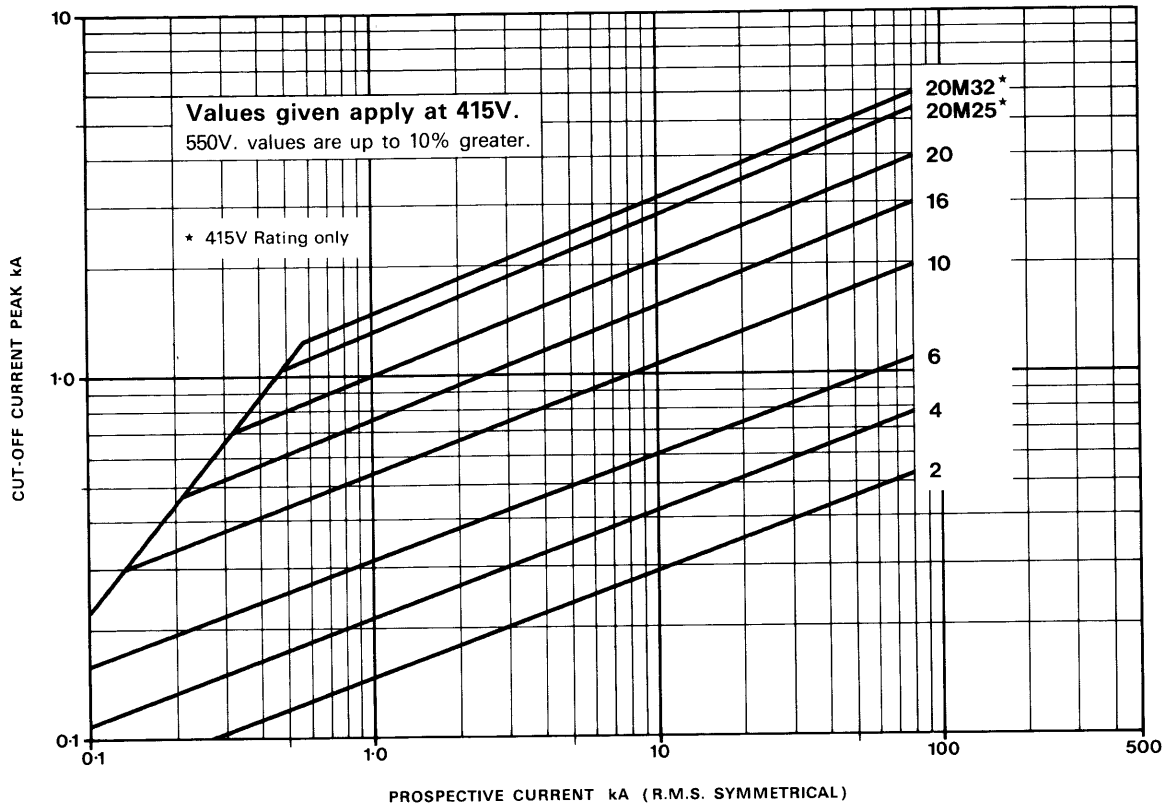

I²t Characteristics

