

AVG Ø135mm Rotating Beacons with Buzzer



SIGNAL LIGHTS



- Incandescent type
- Red, Yellow, Green and Blue lens available
- Smooth lens
- Large rotating reflector
- Long life
- Stud mounted
- Optional Wall Mounting Bracket (MAM-DS27) available
- Buzzer (80dB) model available


Order Information

AVG	B	-	012	-	R										
<table border="1"> <thead> <tr> <th colspan="2">Lens Colors</th> </tr> </thead> <tbody> <tr> <td>R</td> <td>Red</td> </tr> <tr> <td>Y</td> <td>Yellow</td> </tr> <tr> <td>G</td> <td>Green</td> </tr> <tr> <td>B</td> <td>Blue</td> </tr> </tbody> </table>						Lens Colors		R	Red	Y	Yellow	G	Green	B	Blue
Lens Colors															
R	Red														
Y	Yellow														
G	Green														
B	Blue														
<table border="1"> <thead> <tr> <th colspan="2">Power Supply</th> </tr> </thead> <tbody> <tr> <td>01</td> <td>DC 12V</td> </tr> <tr> <td>02</td> <td>DC 24V</td> </tr> <tr> <td>10</td> <td>AC 110V</td> </tr> <tr> <td>20</td> <td>AC 220V</td> </tr> </tbody> </table>						Power Supply		01	DC 12V	02	DC 24V	10	AC 110V	20	AC 220V
Power Supply															
01	DC 12V														
02	DC 24V														
10	AC 110V														
20	AC 220V														
<table border="1"> <thead> <tr> <th colspan="2">Light Style</th> </tr> </thead> <tbody> <tr> <td></td> <td>Rotating Light</td> </tr> <tr> <td>B</td> <td>Rotating Light with Buzzer</td> </tr> </tbody> </table>						Light Style			Rotating Light	B	Rotating Light with Buzzer				
Light Style															
	Rotating Light														
B	Rotating Light with Buzzer														

Specifications


Model	AVG	AVGB
Bulb Type	Incandescent	
Power Supply	12VDC, 24VDC, 110VAC, 220VAC	
Current Draw & Wattage	12VDC	2.08A, 25W
	24VDC	1.04A, 25W
	110VAC	0.22A, 25W
	220VAC	0.11A, 25W
Sound Level	—	80 dB
Rotation Rate	150 times/minute	

Dimensions

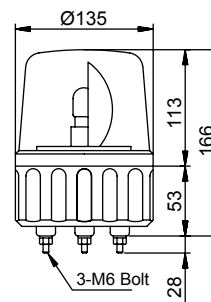

unit: mm

Stud Mount Hole Layout

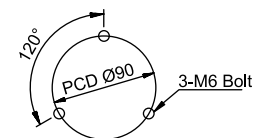


Optional Orders

Replacement Parts

Bulb	Part Number	Specifications
	MAB-T15-D-012-25	12V DC, 25 Watt
	MAB-T15-D-024-25	24V DC, 25 Watt
	MAB-T15-D-130-25	110V AC, 25 Watt
	MAB-T15-D-240-25	220V AC, 25 Watt
Lens	LENS-AVG-(□)	Smooth Lens for Rotating Lights

(□): indicates color of Lens; R, Y, G or B

Wall Mount Brackets

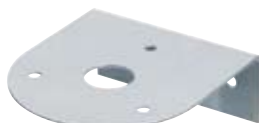


MAM-DS27

NOTE: See Page 14 for Dimensions.

Wiring Diagram

DC 12V & DC 24V

AVG-01-□ AVGB-01-□
AVG-02-□ AVGB-02-□

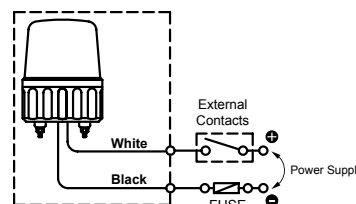

AC 110V & AC 220V

AVG-10-□ AVGB-10-□
AVG-20-□ AVGB-20-□

