


Metric Pan head machine screws - PoziDriv®

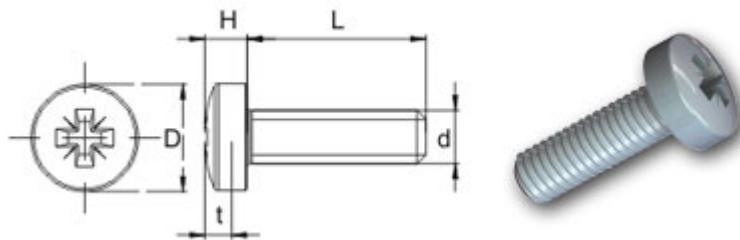

DIN 7985
BS 4183
ISO 7045

Materials/Finishes:

Steel 4.8/Zinc & clear
Stainless steel/Self colour
Brass/Self colour

Dimensions

Thread (d)	M1.6	M2	M2.5	M3	M3.5	M4	M5	M6	M8
D nom	3.2	4	5	6	7	8	10	12	16
Recess No.	0	0	1	1	2	2	2	3	4
Head H max (DIN)	1.4	1.7	2.1	2.5	2.8	3.25	3.95	4.75	6.1
Head H max (BS)	-	-	1.75	2.1	2.45	2.8	3.5	4.2	5.6
Head H max (ISO)	-	1.6	2.1	2.4	2.6	3.1	3.7	4.6	6

NB: Generally our preferred stock is to DIN - if dimensions are critical to your application you should check with us prior to ordering.

Preferred lengths

		Thread (d)								
		M1.6	M2	M2.5	M3	M3.5	M4	M5	M6	M8
Length (L)	3	ST								
	4	ST	ST	ST A2	ST A2					
	5	ST	ST	ST A2	ST A2		ST			
	6	ST	ST	ST A2	ST A2		ST A2	ST A2		
	8	ST	ST	ST A2	ST A2		ST A2	ST A2	ST A2	ST
	10		ST	ST A2	ST A2		ST A2	ST A2	ST A2	ST
	12		ST	ST A2	ST A2		ST A2	ST A2	ST A2	ST
	16		ST	ST A2	ST A2		ST A2	ST A2	ST A2	ST
	20		ST	ST A2	ST A2		ST A2	ST A2	ST A2	ST
	25			ST A2	ST		ST A2	ST A2	ST A2	ST
	30				ST		ST A2	ST A2	ST A2	ST
	35				ST		ST	ST A2	ST A2	ST

	40			ST		ST	ST	ST	ST
	45			ST		ST	ST	ST	ST
	50			ST		ST	ST	ST	ST
	60					ST	ST	ST	ST
	70					ST	ST	ST	ST
	80					ST	ST	ST	ST
	90						ST	ST	ST
	100						ST	ST	ST

ST - Steel, Zinc & clear - other finishes often available

A2 - A2 Stainless steel, Self colour