


Pan head Tap-Fix screws - PoziDriv®

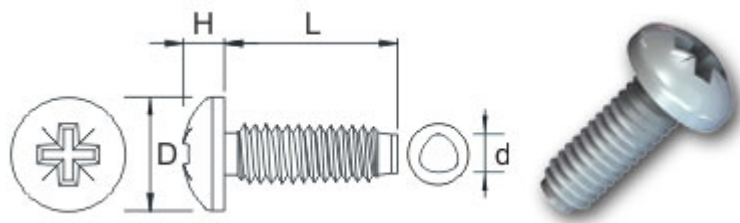

For metals
Three-lobed threadform

Materials/Finishes:

Case hardened steel/Zinc & clear de-embrittled

Dimensions

d	M2	M2.5	M3	M3.5	M4	M5	M6
D	4	5	6	7	8	10	12
H	1.72	2.12	2.52	2.82	3.25	3.95	4.7
Recess - min	1.1	1.27	1.68	1.65	1.9	2.64	3
Penetration - max	1.35	1.52	1.93	2.11	2.36	3.1	3.4
Recess No.	1	1	1	2	2	2	3

Preferred lengths

		Thread (d)						
		M 2	M 2.5	M 3	M 3.5	M 4	M 5	M 6
Length (L)	5		ST	ST				
	6		ST	ST		ST	ST	
	8		ST	ST		ST	ST	
	10		ST	ST		ST	ST	ST
	12			ST		ST	ST	ST
	16		ST	ST		ST	ST	ST
	20			ST		ST	ST	ST
	25					ST	ST	ST
	30					ST	ST	ST
40						ST	ST	

ST - Steel, Zinc & clear
A2 - Stainless steel