




Visual Signals FLASHING FILAMENT

BEACONS

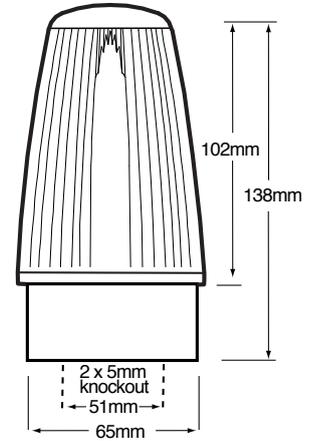

Industrial Flashing Filament Beacons > FF125 Series

Product overview

The FF125 Series operates through an internal circuit which simply cycles the lamp On and Off. These type of beacons generally give a much lower light output as it takes longer for the lamp to

fully illuminate itself. These units are supplied with a filament lamp. In terms of light coverage, this type of beacon is more efficient as it illuminates the whole surface of the beacon constantly through 360 degrees. The FF125 series is ideal for low cost, local signal applications.

Features

- Continuously rated
- Easy to clean external lens
- Suitable for surface or wall mounting
- Optional wall bracket & protective guard available - see accessory page
- 360° visibility
- IP65

Material

- UV Stable Polycarbonate Lens
- UV Stable ABS Plastic Base

Code No:	Voltage:	Light Source:	Current:
FF125-80	12v Dc ---	Ba15d x 21w	1.75 A
FF125-81	24v Dc ---	Ba15d x 21w	0.88 A
FF125-82	115v Ac ~	Ba15d x 15w	0.13 A
FF125-83	230v Ac ~	Ba15d x 15w	0.07 A



Kg 0.20

50/60 **Hz**

°C -25+55

IP 65

FPM 60

INDUSTRIAL

APPROVAL AND CONFORMITIES



ADD THE FOLLOWING LENS CODES TO THE PRODUCT CODE WHEN ORDERING

01 02 03 04 05