





for your electronic home



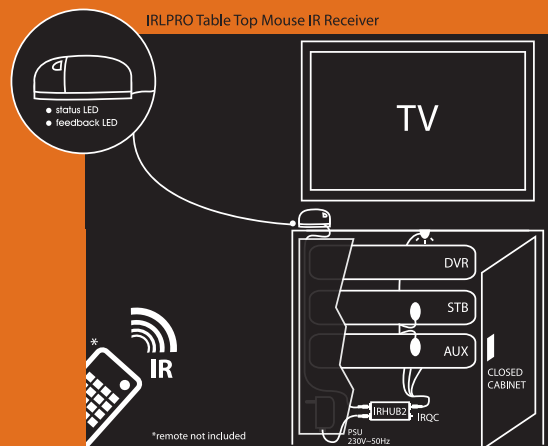

Our ebode proprietary eIR²x™ (pronounce Irex) Technology guarantees a high level of immunity for InfraRed noise from direct sunlight, CFL lighting and Flat Panel TV's (including Plasma, LCD and LED). This kit contains one 3IREDB for control of 3 devices, and a 1IRQC Quick Connect cable for direct control of popular Audio/Video Receivers (e.g. Yamaha, Onkyo, Denon, Marantz, NAD, Harman Kardon etc). The IR Link Pro runs on a 12VDC mains adapter (included) and is expandable with extra IR Link Receivers in different rooms.


 The ebode IR Link Pro is a mains powered InfraRed Extender System that allows full remote control operation of audio/video components (such as your Blu-ray Player, A/V Receiver, DVR, Satellite Box, Cable Tuner, etc.) which are located behind closed cabinet doors, in other rooms, or other concealed and/or out-of-sight locations.


 Mit dem IR Link Pro können Sie die InfraRot Signale von Ihrer eigenen Fernbedienung verlängern. Der IR Link Pro macht es möglich, Ihre Audio/Video Geräte zu bedienen, auch wenn diese in einem anderen Raum oder in einem abgeschlossenen Schrank untergebracht sind oder außer Reichweite stehen.


 Met de IR Link Pro kunt u de InfraRood signalen van uw eigen afstandsbediening verlengen. IR Link Pro maakt het mogelijk om uw A/V apparatuur te bedienen terwijl deze in een andere ruimte of gesloten kast staat of verdekt is opgesteld.

 IR Link Pro är ett InfraRött förlängningssystem som tillåter fjärrstyrning av AV-utrustning, och som är t ex lokaliserade bakom stängda dörrar i andra rum, eller andra områden som är utom synhåll.


 Le IR Link Pro est un système d'extension InfraRouge qui permet de contrôler à distance des équipements A/V situés dans d'autres chambres, derrière un placard fermé, cachés ou tout simplement hors de portée.


 El IR Link Pro permite pleno control remoto por InfrarRojos sobre diferentes equipos de A / V situados ocultos tras muebles con puertas cerradas, en otras habitaciones, o en otros lugares cerrados o fuera del alcance de la vista.

 O IR Link Pro é um sistema extensor de InfraVermelhos que permite o controlo remoto de equipamentos A/V que situem dentro de armários, em locais escondidos ou fora de vista.

 IR Link Pro è un Sistema di Ripetizione a InfraRossi che consente di utilizzare il Telecomando a InfraRossi per comandare apparecchiature multimediali Audio/Video poste all'interno di cabinet chiusi, in altri ambienti e/o in altre postazioni non in vista.

PLASMA, LCD and LED proof

 entertainment

 eIR²x™

wide band 30-60 kHz incl
NEC, RC5/6, RCMM, XMP, etc.

- IRLPRO Table Top Mouse IR Receiver (55x40x25mm)
- IRHUB2 Connecting Hub
- 3IREDB Emitters for control of up to 3 devices
- 1IRQC IR Quick Connect cable
- 230V~50Hz to 12VDC Mains Power Supply Adapter
- Instruction Manual
- OPTIONAL Expansion kit: 3IREDB IR Emitters for additional control of 3 devices

More from ebode



TAKE10 IR+RF



TAKE6 IR



VL58



LightSpeaker™

www.ebodeelectronics.eu

Available Plug Types: Australian, European (Schuko) and UK plug types



APPLICATIONS	IR Link B Battery	IR Link P Power Supply	PM10C / PM18 PowerMid	IR Link C Coax	IR Link Pro	IR Link Pro Mini	IR Link Pro Flush	CI IR Link Pro Modular
Operate A/V equipment that is located in a closed cabinet	•	•	•	•	•	•	•	
Operate A/V equipment that is located in another room			•	•	•	•	•	
Number of A/V devices to be operated with IR Link Extender Kit	3	3	unlimited in range of blaster	3	4 (3ired+ 1irqc)	7 2x3ired+1irqc	7 2x3ired+1irqc	
Max. number of A/V devices controlled with optional Emitters	3	6	N/A		6	12	12	
FEATURES								
Signal transmission infrastructure								
• Via IR extender cable attached	•	•						
• Wireless RF (433 MHz)			•					
• Via coaxial cable (CATV/CAI)				•				
• With category cable or similar					•	•	•	
Max. distance between A/V equipment and remote room	3 meters	3 meters	30 meters indoor*	300 meters	300 meters	300 meters	300 meters	
Optional custom receiver expansion					•	•	•	
Works with original remote control	•	•	•	•	•	•	•	
IR carrier frequency range	30 - 60kHz	30 - 60kHz	38 + 56 kHz	30 - 60kHz	30 - 60kHz	30 - 60kHz	30 - 60kHz	30 - 60kHz
RCMM / XMP compatible	•	•		•	•	•	•	
eIR2x** immunity for interference	•	•		•	•	•	•	
Power Status Feature					•	•	•	
Battery powered	•		• (PM18)		•	•	•	
230V ~ mains power adapter		•	• (PM10C)	•	•	•	•	•

FOR THE CERTIFIED DEALER/INSTALLER:
EBODE IRLINK MODULAR SERIES
 VISIT WWW.EBODEELECTRONICS.EU

* depending on environmental conditions

** Our ebode proprietary eIR2x™ (pronounce Irex) Technology guarantees a high level of immunity for InfraRed noise from direct sunlight, CFL lighting and Flat Panel TV's (including Plasma, LCD and LED).