 
 
 



Sensor cables

Connecting cables
M12 to M12
A-coded
shielded

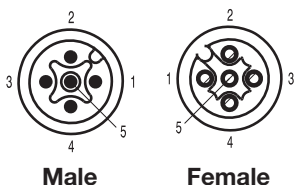

Ordering data

| | |
|--|-------|
| Male, straight - Female, straight | |
| PUR halogen-free | 1.5 m |
| Male, straight - Female, angled | |
| PUR halogen-free | 1.5 m |
| Male, angled - Female, angled | |
| PUR halogen-free | 1.5 m |
| Note | |

3-pole

| Type | Order No. |
|---------------------------|------------|
| SAIL-M12GM12G-3S1.5Q | 1058490150 |
| SAIL-M12GM12W-3S1.5Q | 1059470150 |
| SAIL-M12WM12W-3S1.5Q | 1059720150 |
| Other versions on request | |

4-pole

| Type | Order No. |
|---------------------------|------------|
| SAIL-M12GM12G-4S1.5Q | 1058500150 |
| SAIL-M12GM12W-4S1.5Q | 1059480150 |
| SAIL-M12WM12W-4S1.5Q | 1059730150 |
| Other versions on request | |

5-pole

| Type | Order No. |
|---------------------------|------------|
| SAIL-M12GM12G-5S1.5Q | 1058510150 |
| SAIL-M12GM12W-5S1.5Q | 1059540150 |
| SAIL-M12WM12W-5S1.5Q | 1059740150 |
| Other versions on request | |

Standard cable lengths

| | | |
|--|--------|------------|
| All cables listed under the ordering data have a length of 1.5 metres. The last four ordering digits must be changed when ordering other standard cable lengths. | 1.5 m | xxxxxx0150 |
| | 3.0 m | xxxxxx0300 |
| | 5.0 m | xxxxxx0500 |
| | 10.0 m | xxxxxx1000 |

Technical data

| | |
|---|--|
| Rated current | 4 A |
| Protection class | IP 67 |
| Core cross-section | 0.34 mm ² |
| Contact surface | gold-plated |
| Temperature range of housing | -25...+85 °C |
| Rated voltage | 250 V (3- and 4-pole) / 125 V (5-pole) |
| (acc. to VDE standard 0110 ISO group C) | |

Chapter W includes additional technical specifications for the cable

Dimensioned drawing

