

OPEN-END WRENCHES



OPEN-END WRENCHES - METRIC

- ISO 691 - ISO 1711-1 - ISO 3318 - ISO 10102 - DIN 3110

- Open end angled at 15° from handle axis.

- Forged in Chrome Vanadium steel.

- High chrome finish.

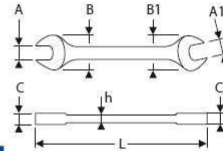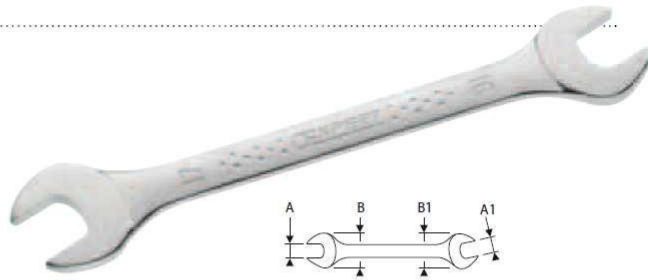

	A (mm/°)	A1 (mm/°)	L (mm)	B (mm)	B1 (mm)	h (mm)	Weight (g)		EAN	List Price
E113262B	4	5	112	12,50	14,50	3,20	15	1	3258951132623	
E113250B	6	7	122	16	18,00	3,30	20	1	3258951132500	
E113251B	8	9	140	20	22,00	3,60	32	1	3258951132517	
E113265B	8	10	140	20	22,00	3,60	32	1	3258951132654	
E113252B	10	11	156	23,40	25,40	4,60	47	1	3258951132524	
E113267B	10	13	172	25,80	28,40	5,10	62	1	3258951132678	
E113268B	11	13	172	27,20	28,40	5	62	1	3258951132685	
E113253B	12	13	172	27,20	28,40	5,10	63	1	3258951132531	
E113272B	13	17	188	31,40	33,90	5,60	88	1	3258951132722	
E113254B	14	15	188	31,40	33,90	5,60	92	1	3258951132548	
E113255B	16	18	204	35,90	38,20	6,10	118	1	3258951132555	
E113275B	17	19	220	38,40	41,90	6,50	158	1	3258951132753	
E113256B	18	19	220	38,40	41,90	6,50	146	1	3258951132562	
E113257B	20	22	234	42	45,90	7,20	200	1	3258951132579	
E113258B	21	23	247	45,20	48,40	7,50	220	1	3258951132586	
E113279B	22	24	247	45,20	48,40	7,50	234	1	3258951132791	
E111201B	24	26	266	50,40	55,90	8,20	318	1	3258951112014	
E113259B	24	27	266	50,40	55,90	8,20	375	1	3258951132593	
E113260B	25	28	285	53,40	61,90	8,40	377	1	3258951132609	
E113261B	26	28	285	53,40	61,90	8,40	456	1	3258951132616	
E113281B	27	29	302	58,30	62,70	9,10	456	1	3258951132814	
E113282B	27	30	302	58,30	62,70	9,10	481	1	3258951132821	
E113909B	30	32	302	59,90	64,90	9,10	600	1	3258951139097	
E113285B	33	35	319	64,40	78,00	10,20	612	1	3258951132852	
E113287B	34	36	319	64,40	78,00	10,20	918	1	3258951132876	
E113286B	36	41	380	74,30	85,40	12,20	918	1	3258951132869	
E113288B	38	42	380	74,30	85,40	12,20	918	1	3258951132883	
E111202B	41	46	415	85	94,00	14,70	1.450	1	3258951112021	
E111203B	46	50	465	94	103,00	15,70	1.767	1	3258951112038	