


Ordering number FA11908
Description FA11908_CXM-SS

Family Rose
 Type Lens
 LED XM-L
 Color White
 Diameter 21.6 mm
 Height 13 mm
 Style Square
 Optic Material PC
 Holder Material PC
 Fastening -
 Status Ready


FWHM degrees
 Efficiency -
 cd/lm -
 Gerber File Available

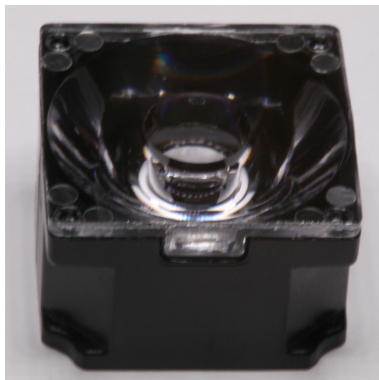

Ordering number FA11909
Description FA11909_CXM-RS

Family Rose
 Type Lens
 LED XM-L
 Color White
 Diameter 21.6 mm
 Height 13 mm
 Style Square
 Optic Material PC
 Holder Material PC
 Fastening -
 Status Ready

FWHM degrees
 Efficiency 84
 cd/lm -
 Gerber File Available

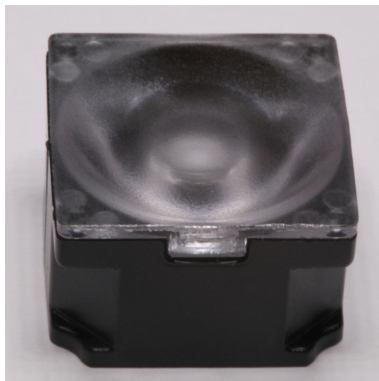

Ordering number FA11910
Description FA11910_CXM-D

Family Rose
 Type Lens
 LED XM-L
 Color White
 Diameter 21.6 mm
 Height 13 mm
 Style Square
 Optic Material PC
 Holder Material PC
 Fastening -
 Status Ready

FWHM degrees
 Efficiency 84
 cd/lm -
 Gerber File Available



Ordering number FA11911
Description FA11911_CXM-M

Family Rose
 Type Lens
 LED XM-L
 Color White
 Diameter 21.6 mm
 Height 13 mm
 Style Square
 Optic Material PC
 Holder Material PC
 Fastening -
 Status Ready

FWHM degrees
 Efficiency 82
 cd/lm -
 Gerber File Available

Rose CXM series



Ordering number FA11912
Description FA11912_CXM-O

Family	Rose	FWHM	degrees
Type	Lens	Efficiency	80
LED	XM-L	cd/lm	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13 mm		
Style	Square		
Optic Material	PC		
Holder Material	PC		
Fastening	-		
Status	Ready		



Ordering number FA11942
Description FA11942_CXM-W

Family	Rose	FWHM	degrees
Type	Lens	Efficiency	79
LED	XM-L	cd/lm	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13 mm		
Style	Square		
Optic Material	PC		
Holder Material	PC		
Fastening	-		
Status	Ready		