

DATA SHEET

STONTRONICS


THE POWER TO SUPPLY

PART NO: S 2217MN

ISSUE NO: 1

CATALOGUE NO: AD-090300BS2.1

RoHS

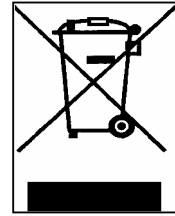

CUSTOMER NO: N/A

DESCRIPTION 9Vdc 300mA UK Plug Top Adaptor



INPUT VOLTS	230Vac
FREQUENCY	50Hz
MAG CURRENT (max.)	30mA
O/P VOLTS NO LOAD	
O/P VOLTS NO LOAD	12.6Vdc
O/P VOLTS	
O/P CURRENT	
O/P VOLTS	9.0Vdc
O/P CURRENT	300mA
FLASH TEST	3.75KVdc
OUTPUT CONNECTOR	2.1x5.5x12mm
OUTPUT POLARITY	Centre +VE
LEAD LENGTH	1.8Mtr
APPROVALS	N/A
LENGTH	68mm
DEPTH	50mm
WIDTH	50mm
WEIGHT	260grams

LABELLING:

Stontronics Ltd
AC-DC ADAPTOR
 MODEL : S2217MN
 INPUT: 230V~50Hz 6.8W - ⊕ +
 OUTPUT: 9V 300mA 2.7VA

- MATERIAL : PVC SHEET
- BASE : BLACK COLOUR
- WORDS : WHITE COLOUR
- SIZE : 32 x 27mm

SCHEMATIC:

