


# XZCP1340L5

female - M12 - 3-pin - elbowed prewired  
connector - cable 5 m

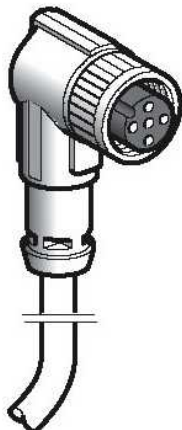

## Main

Accessory / separate part category	Cabling accessories
Accessory / separate part type	Pre-wired connectors
Series name	General purpose
Electrical connection	Elbowed female connector M12, 3 pins
Collar material	Metal
Status LED	2 PNP LEDs
Cable length	5 m

## Complementary

Cable connector fixing	Screw-on
Cable outer diameter	5.2 mm
Cable composition	3 x 0.34 mm <sup>2</sup>
Wire insulation material	PUR
[Ue] rated operational voltage	10...30 V DC
[In] rated current	4 A
Contact resistance	<= 5000 µOhm
Insulating resistance	>= 1 GΩ
Product weight	0.18 kg

## Environment

IP degree of protection	IP67
Ambient air temperature for operation	-35...90 °C (static) -5...90 °C (flexing)
Ambient air temperature for storage	-35...100 °C
RoHS EUR status	Compliant
RoHS EUR conformity date	0649

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.