 
 





CCTV SYSTEMS

Monitors & Accessories


2011 Range




Monitors Range




Order Code
XTM010




Order Code
XTM020



Order Code
X5LCD



Order Code
X8LCD



Order Code
X19LCD



DESIGNED
IN THE UK

Key Features

Xvision Test Monitors and Professional CCTV Monitors provide the best quality images for commissioning and viewing of CCTV systems.

Designed with the environment in mind they offer excellent performance and consume less energy than previous models.

Xvision Test Monitor Features

- Designed for Installers

Ideal for use by both CCTV professionals & the occasional CCTV user, our test monitors allow quick and easy checking of cameras and associated equipment.



- Handy and totally portable

Designed to be versatile in use, both monitors can be battery powered and are supplied with additional straps allowing it to be attached to you, leaving you free to use both hands to install, focus and adjust the camera.

- Lens Testing on site

The multi function XTMO20 is much more than a test monitor. It has a built in Colour Camera and selection of lenses allowing it to be used for

1. Testing the Video Output of equipment
2. Focusing and Positioning Cameras
3. Testing the Video Input of equipment
4. Seeing the angle of view given by a 4.0, 6.0, 8.0, 12.0 and 16.0mm lens during site surveys



Xvision Monitor Features

- High Resolution Images

Xvision monitors provide excellent performance and offer better resolution images than non CCTV monitors, ideal for use with high resolution analogue cameras and VGA/HDMI DVRs

- Loophroughs

For larger systems this feature allows the video signal to be passed through the monitor and sent to an additional monitor. This is helpful in a CCTV environment where many people may need to view the same scene.

- 3D Noise Filter

This technology filters out digital noise and pixelation that can occur when using analogue CCTV inputs with an LCD screen. It also minimises motion blur and image flickering.

- Versatile Monitor Inputs

Xvision monitors offer a variety of connections including, BNC, VGA, HDMI and SVHS. This makes them suitable for a variety of applications and very versatile.

- Built in speakers









Our top of the range X19LCD monitor features built in speakers for use with CCTV equipment that supports audio.

Compare the Range


MONITORS

| Image & Brand | |  |  |  |  |  |
|---------------|------------------------------------|---|---|--|---|---|
| Model Number | | XTM010 | XTM020 | X5LCD | X8LCD | X19LCD |
| TYPE | Style | Test Monitor | Test Monitor | CCTV Monitor | CCTV Monitor | CCTV Monitor |
| | Dimensions (WHD) (without bracket) | 85 x 64 x 21mm | 87 x 155 x 48mm | 150 x 120 x 28mm | 205 x 173 x 29mm | 510 x 430 x 70mm |
| | Warranty | 1 Year | 1 Year | 2 Years | 2 Years | 2 Years |
| FEATURES | Screen Size & Type | 2.5" LCD | 3.5" LCD | 5" LCD | 8" LCD | 19" LCD |
| | Resolution | 480 x 234 | 480 x 234 | 640 x 480 | 800 x 600 | 1280 x 1024 |
| | Audio | | | ✓ | ✓ | ✓ |
| | 3D Noise Filter | | | ✓ | ✓ | ✓ |
| | Loophroughs | | | | | ✓ |
| | Remote Control | N/A | N/A | ✓ | ✓ | ✓ |
| | Mount Type | On Person (adjustable strap supplied), Desk (bracket supplied) | On Person (adjustable strap supplied), Desk | Wall or Desk Mounting (Ceiling mounting using optional bracket) | Desk Mounting (Wall or Ceiling mounting using optional bracket) | Desk Mounting (Wall or Ceiling mounting using optional bracket) |
| POWER | Operating Voltage | 5V DC | 12V DC 170mA | 12V DC, 2000mA | 12V DC, 2000mA | 100 to 240V AC |
| | Suggested Power Supply | Rechargeable Battery (5V DC 1000mA, supplied) | 12V DC Power Supply (not supplied) or 8 x AA Alkaline Batteries (not supplied) | Supplied | Supplied | Supplied |
| CONNECTIONS | BNC or Phono Input | ✓ | ✓ | ✓ 2x BNC Inputs | ✓ 2x BNC Inputs | ✓ 2x BNC Inputs |
| | VGA Input | | | | ✓ | ✓ |
| | DVI Input | | | | | |
| | HDMI Input | | | | | ✓ |
| | SVHS Input | | | | | ✓ |
| | Audio Input | | | | | ✓ |

MONITOR ACCESSORIES

| Image | Product Code | Description | Brand | Warranty |
|---|----------------|--|---|-----------------|
|  | BNC2VGA | BNC to VGA Adaptor |  | 1 Year Warranty |
|  | MONCL1 | 1 Metre DVR to Monitor Lead (BNC, Scart or Phono connections) Connects DVRs to TV/Monitor with Scart, Phono or BNC sockets. |  | 1 Year Warranty |
| | MONCL2 | 20 Metre DVR to Monitor Lead | | |
| | MONCL3 | 40 Metre DVR to Monitor Lead | | |
|  | CSVGA | CAT5 VGA Dongles - RJ45 Type |  | 1 Year Warranty |
|  | VIDAMP | 1 Video Input to 4 Video Output Distributor |  | 1 Year Warranty |

Other products...

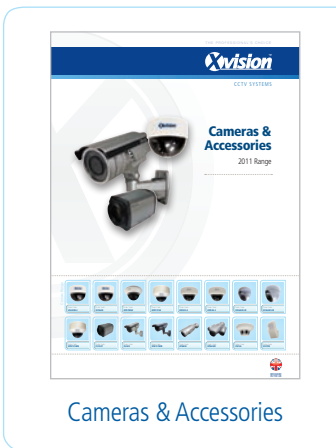


Cameras & Accessories



Speed Domes & Accessories



DVRs & Accessories

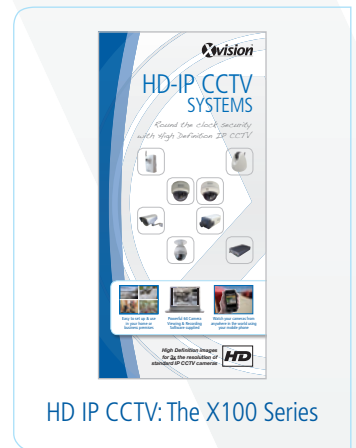

HD IP CCTV: The X100 Series

At Xvision we manufacture a wide range of Professional CCTV products. For further information on our other products visit www.xvision.com to download a PDF or contact your local distributor for a leaflet.



UK HEAD OFFICE
Unit 2, Valley Point,
Beddington Farm Road,
Croydon, Surrey CR0 4WP

Tel: +44 (0)844 947 2411
Fax: +44 (0)844 947 2412
Email: sales@xvision.com
www.xvision.com

AVAILABLE FROM: