

Color-Keyed®



T&B Catalog Number: 54162NT
UPC Number: 78620986789
Description: Copper One-Hole Lug - Standard Barrel Narrow Tongue Lug - max 35KV, 3/0 AWG Wire, 1/4" Bolt Size, Tin Plated with Inspection Hole, Orange 50
Status: Active

WEB_USE

-T&B Product Line 007

General

-Material Copper
 -Finish Tin Plated
 -Wire Size 3/0 AWG
 -Number of Studs 1
 -Stud Size 1/4
 -Tongue Angle Straight
 -Barrel Length Standard
 -Barrel Shape Standard
 -Tongue Width Narrow
 -Peep Hole Y
 -Marking Standard
 -Hole Shape Round
 -Die Color Orange
 -Die Code 50

Dimension Information

-A (inches) 1.680
 -B (inches) 0.650
 -C (inches) 0.632
 -D (inches) 0.125
 -E (inches) 0.632
 -F (inches) 0.250

Tooling

-Connector & Tooling Chart Available on Website

Packaging

-T&B Order Multiple 10
 -T&B Inner Pack 10
 -Package in Units 100
 -T&B Sold in UOM Each
 -T&B Weight Per UOM 7.7 lbs. per 100

Application Support



-T&B Sales Drawings wsd-000288
 -T&B Instruction Sheets ta00675-tb2
 -Connector & Tooling Chart Available on Website

Notes

- Dimensions given for reference only. Dimensions may vary up to +/- .030.

Certifications

-RoHS Compliance Yes

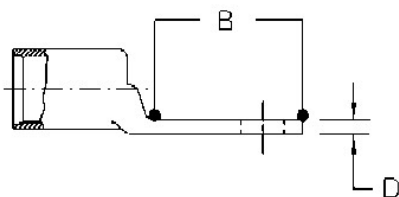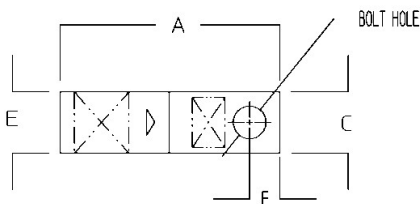

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com