


Sta-Kon®



T&B Catalog Number: B14-10F
UPC Number: 78621080325
Description: Non-Insulated Fork Terminal For Wire Range 18-14 Stud Size #10, Metallic

Status: Active

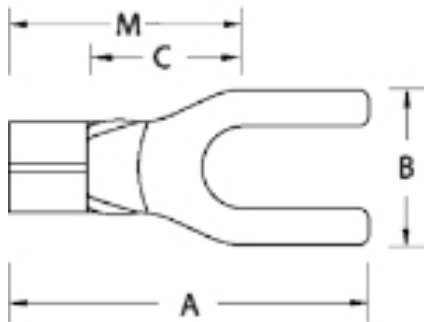

WEB_USE

-T&B Product Line	029
-US Cutsheet PDF Catalog Link	http://www-public.tnb.com/contractor/docs/stakon.pdf

Features

-	These non-insulated fork terminals are made of electrolytic copper for high conductivity. They can be installed with crimping tools having a single indenter or double indenter (recommended for solid wire). Serrated barrel increases grip on wire.
---	-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

General

-Insulation Type	Non-Insulated
-Terminal Series	B
-Material	Copper
-Finish	Electro -Tin Plated
-Color	Metallic
-Wire Range	18-14
-Stud Size	#10

Dimension Information

-Stock Thickness	.03
-A (inches)	.75
-B (inches)	.31
-C (inches)	.27
-M (inches)	.59

Specifications

-Temperature Rating	150°C
-Voltage Rating	600V
-Flammability Rating	UL 94 V-0

Tooling

-Tool Charts	Available on Website
-Application Tools	WT110M, WT111M, WT112M, WT2000, ERG4002
-Recommended Tool	ERG4001

Packaging

-T&B Order Multiple	100
-T&B Inner Pack	100
-Package in Units	500
-Package Type	Standard
-T&B Sold in UOM	Each
-T&B Weight Per UOM	0.23 lbs. per 100
-Alternate Package Qty	B115

Application Support

-Overview	Available on Website
-Wire Guide Tables	Available on Website

Certifications

-RoHS Compliance Yes

Certifications



File Nbr:

E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com