 



Laser Labels Printable Materials Chart 128
 Label Index by Part Number 129
 Label Index by Size 130 – 135
 Circuit Board and Component
 Identification 136 – 138
 Wire and Cable Marking 139

Data Communications
 Equipment and Cabling Labels 140 – 141
 General Identification Labels 142 – 143





Laser Printable Material Chart

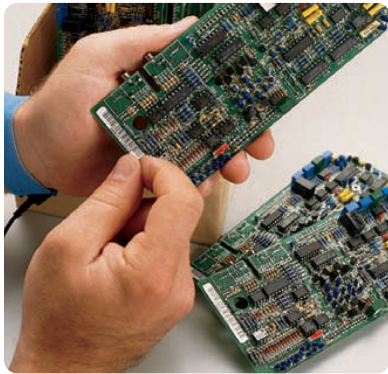


The high resolution of laser printing makes it possible to generate readable, dense bar codes on labels small enough to fit into limited application space. (B-747 pictured)

Type	Max. Service Temp. °C	Colour	Finish	Use	Special Properties
B-799	90	White	Matt	Aerospace and military cable marking	Repositionable
B-124	66	White/Colours	Matt	110 terminal block marking for telecommunications	Available in green, purple, yellow, blue, red, brown, white, orange and grey
B-759	90	White/Colours	Matt	Bar code and general labelling applications	Excellent toner adhesion
B-409	90	White	Matt	Bar code labels and general identification	Abrasion resistant
B-410	100	White	Matt	Tamper-evident label	Label destroys upon removal
B-361	110	Clear/White	Matt	Wire and cable marking, self-laminating	Low halogen and sulphur content
B-707	130	White	Matt	Electronic component labelling; general identification	Rough surface application; Stronger bond to low surface energy plastics  
B-709	70	White	Matt	Electronic component, bar code labels and general temporary identification	Removable
B-712	105	Clear	Matt	Electronic component labelling; general identification	Rough surface application; Stronger bond to low surface energy plastics
B-722	105	Clear	Matt	Rating plates, name plates, general-purpose printable overlaminate	Translucent
B-747	130	White/Yellow	Matt	Electronic PCB component, bar code labels and equipment labelling	Excellent solvent and smudge resistance; high-resolution printing; available in white only HF  
B-773	120	Silver	Matt	Rating plates and electronic component marking	Adheres to a variety of surfaces; metallized HF  
B-652	300 *	Amber	Matt	Bottom PC board and SMT component marking	Withstands extremely high temperatures
B-737	130	White	Matt	Aerospace and military cable marking	Repositionable
B-425	90	White	Matt	Rating plates and general-purpose labelling	Excellent abrasion and smudge resistance

Tedlar® is a registered trademark of DuPont.
* 5 minutes

 *These materials are UL recognized.

 *These materials are CSA approved.

HF Halogen free DIN VDE 0472 Part 815

*Refer to the full page charts on pages 280-281 for more information and complete listing of parts.



Label Index by Part Number

LaserTab® Laser-Printable Labels


Order Reference	Size (mm)	Specifications on Page
LAT-1-652	7.62 x 6.35	130
LAT-1-747	7.62 x 6.35	130
LAT-2-652	9.53 x 9.53	130
LAT-2-747	9.53 x 9.53	130
LAT-3-410	16.51 x 6.35	130
LAT-3-652	16.51 x 6.35	130
LAT-3-747	16.51 x 6.35	130
LAT-4-410	20.32 x 6.35	130
LAT-4-652	20.32 x 6.35	130
LAT-4-737	20.32 x 6.35	130
LAT-4-747	20.32 x 6.35	130
LAT-4-747-YL	20.32 x 6.35	130
LAT-5-652	20.32 x 12.70	130
LAT-5-747	20.32 x 12.70	130
LAT-5-747-YL	20.32 x 12.70	130
LAT-5-759	20.32 x 12.70	131
LAT-6-652	25.40 x 6.35	131
LAT-6-747	25.40 x 6.35	131
LAT-7-410	25.40 x 12.70	131
LAT-7-652	25.40 x 12.70	131
LAT-7-707	25.40 x 12.70	131
LAT-7-709	25.40 x 12.70	131
LAT-7-712	25.40 x 12.70	134
LAT-7-722	25.40 x 12.70	131
LAT-7-737	25.40 x 12.70	131
LAT-7-737-YL	25.40 x 12.70	131
LAT-7-747	25.40 x 12.70	131
LAT-7-747-YL	25.40 x 12.70	131
LAT-7-773	25.40 x 12.70	131
LAT-7-799	25.40 x 12.70	131
LAT-8-409	25.40 x 9.53	131
LAT-8-652	25.40 x 9.53	131
LAT-8-707	25.40 x 9.53	134
LAT-8-712	25.40 x 9.53	134
LAT-8-747	25.40 x 9.53	131
LAT-8-747-YL	25.40 x 9.53	131
LAT-8-799	25.40 x 38.10	131
LAT-9-409	38.10 x 6.35	131
LAT-9-652	38.10 x 6.35	131
LAT-9-709	38.10 x 6.35	131
LAT-9-747	38.10 x 6.35	131
LAT-9-747-YL	38.10 x 6.35	131
LAT-9-799	38.10 x 6.35	131
LAT-10-652	47.63 x 6.35	132
LAT-10-747	47.63 x 6.35	132
LAT-11-409	47.63 x 9.53	132
LAT-11-747	47.63 x 9.53	132
LAT-11-747-YL	47.63 x 9.53	132
LAT-12-652	76.20 x 9.53	132
LAT-12-709	76.20 x 9.53	132
LAT-12-747	76.20 x 9.53	132
LAT-12-747-YL	76.20 x 9.53	132
LAT-13-409	47.63 x 21.16	132
LAT-13-410	47.63 x 21.16	132
LAT-13-707	47.63 x 21.16	132
LAT-13-712	47.63 x 21.16	132
LAT-13-722	47.63 x 21.16	132
LAT-13-747	47.63 x 21.16	132
LAT-13-747-YL	47.63 x 21.16	132
LAT-13-759	47.63 x 21.16	132
LAT-14-747	47.63 x 33.78	132
LAT-15-361	12.70 x 19.05	133
LAT-16-361	25.40 x 19.05	133
LAT-17-361	25.40 x 25.40	133
LAT-18-361	25.40 x 33.78	133
LAT-19-361	25.40 x 80.44	133
LAT-20-773	38.10 x 19.05	131
LAT-21-707	63.50 x 25.40	132
LAT-21-712	63.50 x 25.40	132

Order Reference	Size (mm)	Specifications on Page
LAT-21-747	63.50 x 25.40	132
LAT-21-747-YL	63.50 x 25.40	132
LAT-21-773	63.50 x 25.40	132
LAT-22-361	12.70 x 38.10	133
LAT-23-747	25.40 x 12.70	133
LAT-23-773	25.40 x 12.70	133
LAT-24-747	44.45 x 25.40	133
LAT-24-773	44.45 x 25.40	133
LAT-25-652	12.70 x 11.10	130
LAT-25-709	12.70 x 11.10	130
LAT-25-747	12.70 x 11.10	130
LAT-26-652	6.35 x 6.35	130
LAT-26-747	6.35 x 6.35	130
LAT-27-361	47.63 x 80.44	133
LAT-28-409	215.90 x 279.40	135
LAT-28-722	215.90 x 279.40	135
LAT-28-747	215.90 x 279.40	135
LAT-28-747-YL	215.90 x 279.40	135
LAT-28-773	215.90 x 279.40	135
LAT-29-652	16.51 x 5.08	130
LAT-29-737	16.51 x 5.08	130
LAT-29-747	16.51 x 5.08	130
LAT-29-747-YL	16.51 x 5.08	130
LAT-29-799	15.51 x 5.08	130
LAT-30-737	31.75 x 9.53	131
LAT-30-737-YL	31.75 x 9.53	131
LAT-31-707	50.80 x 22.86	132
LAT-31-747	50.80 x 22.86	132
LAT-31-759	50.80 x 22.86	132
LAT-32-747	76.20 x 22.86	132
LAT-32-759	76.20 x 22.86	132
LAT-33-707	50.80 x 36.50	132
LAT-33-747	50.80 x 36.50	132
LAT-33-759	50.80 x 36.50	132
LAT-34-707	76.20 x 36.50	132
LAT-34-747	76.20 x 36.50	132
LAT-34-759	76.20 x 36.50	132
LAT-35-361	30.48 x 38.10	133
LAT-36-773	40.64 x 9.62	131
LAT-37-799	20.32 x 36.50	131
LAT-38-799	12.70 x 36.50	130
LAT-39-799	25.40 x 36.50	131
LAT-40-799	12.70 x 19.05	130
LAT-41-707	38.10 x 9.53	134
LAT-41-712	38.10 x 9.53	134
LAT-42-707	14.22 x 14.22	130
LAT-42-712	14.22 x 14.22	130
LAT-43-707	73.02 x 9.53	132
LAT-44-707	91.44 x 9.53	132
LAT-45-707	12.70 x 9.53	134
LAT-45-712	12.70 x 9.53	134
LAT-46-707	12.70 x 12.70	134
LAT-46-712	12.70 x 12.70	134
LAT-47-707	38.10 x 12.70	134
LAT-47-712	38.10 x 12.70	134
LAT-175-124	77.77 x 12.70	134
LAT-175-124-BL	77.77 x 12.70	134
LAT-175-124-BR	77.77 x 12.70	134
LAT-175-124-GR	77.77 x 12.70	134
LAT-175-124-GY	77.77 x 12.70	134
LAT-175-124-OR	77.77 x 12.70	134
LAT-175-124-PL	77.77 x 12.70	134
LAT-175-124-RD	77.77 x 12.70	134
LAT-175-124-YL	77.77 x 12.70	134
LAT-176-124	50.17 x 9.53	134
LAT-177-124	200.81 x 12.07	135
LAT-177-124-BL	200.81 x 12.07	135
LAT-177-124-BR	200.81 x 12.07	135
LAT-177-124-GR	200.81 x 12.07	135

Order Reference	Size (mm)	Specifications on Page
LAT-177-124-GY	200.81 x 12.07	135
LAT-177-124-OR	200.81 x 12.07	135
LAT-177-124-PL	200.81 x 12.07	135
LAT-177-124-RD	200.81 x 12.07	135
LAT-177-124-YL	200.81 x 12.07	135
LAT-178-759	168.28 x 15.86	135
LAT-178-759-BL	168.28 x 15.86	135
LAT-178-759-BR	168.28 x 15.86	135
LAT-178-759-GR	168.28 x 15.86	135
LAT-178-759-GY	168.28 x 15.86	135
LAT-178-759-OR	168.28 x 15.86	135
LAT-178-759-PL	168.28 x 15.86	135
LAT-178-759-RD	168.28 x 15.86	135
LAT-178-759-YL	168.28 x 15.86	135




European LaserTab® Laser Printable Labels A4 Sheet

Order reference	Size (mm)	Specifications on Page
ELAT-3-747W-10	16.00 x 6.00	130
ELAT-4-747W-10	20.00 x 6.00	130
ELAT-4-747YL-10	20.00 x 6.00	130
ELAT-7-722	25.00 x 13.00	131
ELAT-7-747W	25.00 x 13.00	131
ELAT-7-773	25.00 x 13.00	131
ELAT-8-747W	25.00 x 9.00	131
ELAT-9-747W	38.00 x 6.00	131
ELAT-11-747	47.00 x 9.00	132
ELAT-13-722	47.00 x 21.00	132
ELAT-13-747W	47.00 x 21.00	132
ELAT-13-747-YL	47.00 x 21.00	132
ELAT-15-361-5	12.00 x 19.00	133
ELAT-18-361-2.5	25.00 x 33.00	133
ELAT-19-361	25.00 x 80.00	133
ELAT-21-722	63.00 x 25.00	132
ELAT-21-747-YL	63.00 x 25.00	132
ELAT-21-773	63.00 x 25.00	132
ELAT-27-361-1	47.00 x 80.00	133
ELAT-28-722	210.00 x 297.00	135
ELAT-28-747-W	210.00 x 297.00	135
ELAT-28-747-YL	210.00 x 297.00	135
ELAT-28-773	210.00 x 297.00	135
ELAT-31-747W-10	20.00 x 8.00	130
ELAT-31-747YL-10	20.00 x 8.00	130
ELAT-32-747Y-10	15.00 x 9.00	130
ELAT-32-747Y-10	15.00 x 9.00	130
ELAT-33-747W-2.5	50.00 x 12.00	132
ELAT-34-747W-1	64.00 x 34.00	132
ELAT-35-773-2.5	27.00 x 27.00	131
ELAT-36-773-10	27.00 x 8.00	131
ELAT-37-773-5	27.00 x 12.50	131
ELAT-38-773-2.5	27.00 x 18.00	131
ELAT-39-747W-10	18.00 x 6.00	130
ELAT-40-747W-10	18.00 x 8.00	130
ELAT-40-747YL-10	18.00 x 8.00	130
ELAT-41-747W-10	12.00 x 12.00	130
ELAT-43-124W	101.60 x 7.00	135
ELAT-44-425	30.00 x 10.00	131
ELAT-45-425	30.00 x 10.00	131

 

Label Index by Size

Multiple Labels Across

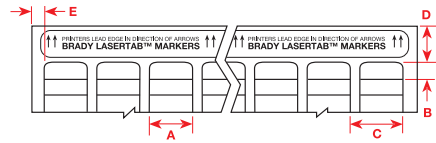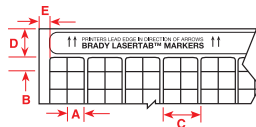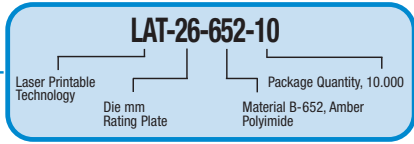

Order Reference Explanation


Most BRADY Order Reference for computer printable labels follow the same four-part format: The first code indicates the technology, the second part is a number indicating the die-sized (where applicable), the third part indicates the BRADY material used (where applicable), and the final code indicates package quantity.

Order Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A (mm)	Label Height B (mm)	Horizontal Repeat C (mm)	Top Margin D (mm)	Left Margin E (mm)	Labels Per Sheet
LAT-26-652-10	10 000	Polyimide	Amber	26	6.35	6.35	15.24	22.23	10.16	936
LAT-26-747-10	10 000	Polyester	White	26	6.35	6.35	15.24	22.23	10.16	936
LAT-1-652-10	10 000	Polyimide	Amber	22	7.62	6.35	17.78	22.23	11.43	836
LAT-1-747-10	10 000	Polyester	White	22	7.62	6.35	17.78	22.23	11.43	836
LAT-2-652-10	10 000	Polyimide	Amber	16	9.53	9.53	12.70	22.23	7.95	400
LAT-2-747-10	10 000	Polyester	White	16	9.53	9.53	12.70	22.23	7.95	400
ELAT-41-747W-10	10 000	Polyester	White	13	12.00	12.00	15.00	20.00	9.00	273
LAT-25-652-10	10 000	Polyimide	Amber	13	12.70	11.10	15.24	22.23	10.16	286
LAT-25-709-10	10 000	Removable Polyester	White	13	12.70	11.10	15.24	22.23	10.16	286
LAT-25-747-10	10 000	Polyester	White	13	12.70	11.10	15.24	22.23	10.16	286
LAT-40-799-1/5	1 000/5 000	Nylon Cloth	White	13	12.70	19.05	15.24	22.23	10.16	156
LAT-38-799-1/2.5	1 000/2 500	Nylon Cloth	White	13	12.70	36.50	15.24	22.23	7.62	78
LAT-42-707-10	10 000	Polyester	Clear	17	14.22	14.22	17.78	22.23	11.94	187
LAT-42-712-10	10 000	Polyester	Clear	17	14.22	14.22	17.78	22.23	11.94	187
ELAT-32-747W-10	10 000	Polyester	White	10	15.00	9.00	19.00	20.00	12.00	290
ELAT-32-747Y-10	10 000	Polyester	Yellow	10	15.00	9.00	19.00	20.00	12.00	290
ELAT-3-747W-10	10 000	Polyester	White	9	16.00	6.00	21.00	14.50	13.00	450
LAT-29-652-10	10 000	Polyimide	Amber	10	16.51	5.08	20.32	22.23	8.26	480
LAT-29-737W-10	10 000	Tedlar®	White	10	16.51	5.08	20.32	22.23	8.26	480
LAT-29-747-2.5/10	2 500/10 000	Tedlar	White	10	16.51	5.08	20.32	22.23	8.26	480
LAT-29-747YL-10	10 000	Polyester	Yellow	10	16.51	5.08	20.32	22.23	8.26	480
LAT-29-799-10	10 000	Nylon Cloth	White	10	16.51	5.08	20.32	22.23	8.26	480
LAT-3-410-10	10 000	Polyolefin	White	10	16.51	6.35	20.32	22.23	8.26	380
LAT-3-652-10	10 000	Polyimide	Amber	10	16.51	6.35	20.32	22.23	8.26	380
LAT-3-747-10	10 000	Polyester	White	10	16.51	6.35	20.32	22.23	8.26	380
ELAT-39-747W-10	10 000	Polyester	White	9	18.00	6.00	21.00	14.50	12.00	396
ELAT-40-747W-10	10 000	Polyester	White	9	18.00	8.00	21.00	20.00	12.00	288
ELAT-40-747YL-10	10 000	Polyester	Yellow	9	18.00	8.00	21.00	20.00	12.00	288
ELAT-4-747W-10	10 000	Polyester	White	7	20.00	6.00	25.00	14.50	20.00	315
ELAT-4-747YL-10	10 000	Polyester	Yellow	7	20.00	6.00	25.00	14.50	20.00	315
ELAT-31-747W-10	10 000	Polyester	White	7	20.00	8.00	25.00	20.00	20.00	224
ELAT-31-747YL-10	10 000	Polyester	Yellow	7	20.00	8.00	25.00	20.00	20.00	224
LAT-4-410-10	10 000	Polyolefin	White	8	20.32	6.35	25.40	22.23	8.89	304
LAT-4-652-10	10 000	Polyimide	Amber	8	20.32	6.35	25.40	22.23	8.89	304
LAT-4-737W-10	10 000	Tedlar	White	8	20.32	6.35	25.40	22.23	8.89	304
LAT-4-747-10	10 000	Polyester	White	8	20.32	6.35	25.40	22.23	8.89	304
LAT-4-747YL-10	10 000	Polyester	Yellow	8	20.32	6.35	25.40	22.23	8.89	304
LAT-5-652-10	10 000	Polyimide	Amber	8	20.32	12.70	25.40	22.23	8.89	152
LAT-5-747-10	10 000	Polyester	White	8	20.32	12.70	25.40	22.23	8.89	152
LAT-5-747YL-10	10 000	Polyester	White	8	20.32	12.70	25.40	22.23	8.89	152


Tedlar® is a registered trademark of DuPont.

 Note: Labels are sorted by width, height, 3 digit material number (within reference).





Label Index by Size

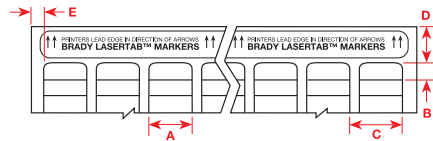


Order Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A (mm)	Label Height B (mm)	Horizontal Repeat C (mm)	Top Margin D (mm)	Left Margin E (mm)	Labels Per Sheet
LAT-5-759-10	10 000	Paper	White	8	20.32	12.70	25.40	22.23	8.89	152
LAT-37-799-1/2.5	1 000/2 500	Nylon Cloth	White	9	20.32	36.50	25.40	22.23	7.62	54
ELAT-8-747W	10 000	Polyester	White	7	25.00	9.00	27.50	14.30	10.00	203
ELAT-7-722	10 000	Polyester	White	7	25.00	13.00	27.50	14.30	10.00	140
ELAT-7-747W	10 000	Polyester	White	7	25.00	13.00	27.50	14.30	10.00	140
ELAT-7-773	10 000	Metallised Polyester	Silver	7	25.00	13.00	27.50	14.30	10.00	140
LAT-6-652-10	10 000	Polyimide	Amber	7	25.40	6.35	27.94	22.23	11.43	266
LAT-6-747-10	10 000	Polyester	White	7	25.40	6.35	27.94	22.23	11.43	266
LAT-8-409-10	10 000	Polyolefin	White	7	25.40	9.53	27.94	22.23	11.43	175
LAT-8-652-10	10 000	Polyimide	Amber	7	25.40	9.53	27.94	22.23	11.43	175
LAT-8-747-10	10 000	Polyester	White	7	25.40	9.53	27.94	22.23	11.43	175
LAT-8-747YL-10	10 000	Polyester	Yellow	7	25.40	9.53	27.94	22.23	11.43	175
LAT-8-799-10	10 000	Nylon Cloth	White	7	25.40	38.10	27.94	22.23	11.43	175
LAT-7-410-10	10 000	Polyolefin	White	7	25.40	12.70	27.94	22.23	11.43	133
LAT-7-652-10	10 000	Polyimide	Amber	7	25.40	12.70	27.94	22.23	11.43	133
LAT-7-707-10	10 000	Polyester	White	7	25.40	12.70	27.94	22.23	11.43	133
LAT-7-709-10	10 000	Removable Polyester	White	7	25.40	12.70	27.94	22.23	11.43	133
LAT-7-722-10	10 000	Polyester	Clear	7	25.40	12.70	27.94	22.23	11.43	133
LAT-7-737-W-10	10 000	Tedlar®	White	7	25.40	12.70	27.94	22.23	11.43	133
LAT-7-737-YL-10	10 000	Tedlar	Yellow	7	25.40	12.70	27.94	22.23	11.43	133
LAT-7-747-10	10 000	Polyester	White	7	25.40	12.70	27.94	22.23	11.43	133
LAT-7-747YL-10	10 000	Polyester	Yellow	7	25.40	12.70	27.94	22.23	11.43	133
LAT-7-773-10	10 000	Metallized Polyester	Silver	7	25.40	12.70	27.94	22.23	11.43	133
LAT-7-799-10	10 000	Nylon Cloth	White	7	25.40	12.70	27.94	22.23	11.43	133
LAT-39-799-1/2.5	1 000/2 500	Nylon Cloth	White	7	25.40	36.50	27.94	22.23	7.62	42
ELAT-36-773-10	10 000	Metallised Polyester	Silver	6	27.00	8.00	31.00	20.00	14.00	192
ELAT-37-773-5	5 000	Metallised Polyester	Silver	6	27.00	12.50	31.00	20.00	14.00	126
ELAT-38-773-2.5	2 500	Metallised Polyester	Silver	6	27.00	18.00	31.00	20.00	14.00	84
ELAT-35-773-2.5	2 500	Metallised Polyester	Silver	6	27.00	27.00	31.00	20.00	14.00	54
ELAT-44-425	750	Polyolefin	White	3	30.00	10.00	64.00	27.00	16.50	30
ELAT-45-425	750	Polyolefin	White	5	30.00	10.00	40.00	24.00	10.00	30
LAT-30-737-W-10	10 000	Tedlar	White	5	31.75	9.53	40.64	22.23	11.43	125
LAT-30-737-YL-10	10 000	Tedlar	Yellow	5	31.75	9.53	40.64	22.23	11.43	125
ELAT-9-747W	10 000	Polyester	White		38.00	6.00	43.00	14.50	21.50	180
LAT-9-409-10	10 000	Polyolefin	White	5	38.10	6.35	40.64	22.23	7.62	190
LAT-9-652-10	10 000	Polyimide	Amber	5	38.10	6.35	40.64	22.23	7.62	190
LAT-9-709-10	10 000	Removable Polyester	White	5	38.10	6.35	40.64	22.23	7.62	190
LAT-9-747-10	10 000	Polyester	White	5	38.10	6.35	40.64	22.23	7.62	190
LAT-9-747YL-10	10 000	Polyester	Yellow	5	38.10	6.35	40.64	22.23	7.62	190
LAT-9-799-10	10 000	Nylon Cloth	White	5	38.10	6.35	40.64	22.23	7.62	190
LAT-20-773-2.5	2 500	Metallised Polyester	Silver	5	38.10	19.05	40.64	22.23	6.35	60
LAT-36-773-1	1 000	Metallised Polyester	Silver	4	40.64	9.53	48.77	22.23	15.75	100


Tedlar® is a registered trademark of DuPont.

 Note: Labels are sorted by width, height, 3 digit material number (within reference).





Label Index by Size

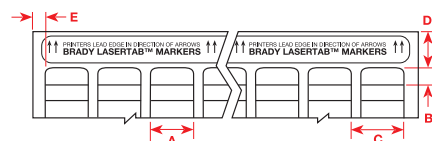


Order Reference	Pieces Per Package	Material	Colour	Labels Per Row	Label Width A (mm)	Label Height B (mm)	Horizontal Repeat C (mm)	Top Margin D (mm)	Left Margin E (mm)	Labels Per Sheet
ELAT-11-747	5 000	Polyester	White	4	47.00	9.00	49.00	14.50	8.00	116
ELAT-13-722	2 500	Polyester	White	4	47.00	21.00	49.00	14.50	8.00	48
ELAT-13-747W	2 500	Polyester	White	4	47.00	21.00	49.00	14.50	8.00	48
ELAT-13-747-YL	2 500	Polyester	White	4	47.00	21.00	49.00	14.50	8.00	48
LAT-10-652-10	10 000	Polyimide	Amber	4	47.63	6.35	50.80	22.23	7.98	156
LAT-10-747-10	10 000	Polyester	White	4	47.63	6.35	50.80	22.23	7.98	156
LAT-11-409-5	5 000	Polyolefin	White	4	47.63	9.53	50.80	22.23	7.87	100
LAT-11-747-5	5 000	Polyester	White	4	47.63	9.53	50.80	22.23	7.87	100
LAT-11-747YL-5	5 000	Polyester	Yellow	4	47.63	9.53	50.80	22.23	7.87	100
LAT-13-409-2.5	2 500	Polyolefin	White	4	47.63	21.16	50.80	21.18	7.87	44
LAT-13-410-2.5	2 500	Polyolefin	White	4	47.63	21.16	50.80	21.18	7.87	44
LAT-13-707-2.5	2 500	Polyester	White	4	47.63	21.16	50.80	21.18	7.87	44
LAT-13-712-2.5	2 500	Polyester	Clear	4	47.63	21.16	50.80	21.18	7.87	44
LAT-13-722-2.5	2 500	Polyester	White	4	47.63	21.16	50.80	21.18	7.87	44
LAT-13-747-2.5	2 500	Polyester	Yellow	4	47.63	21.16	50.80	21.18	7.87	44
LAT-13-747YL-2.5	2 500	Paper	White	4	47.63	21.16	50.80	21.18	7.87	44
LAT-13-759-2.5	2 500	Polyester	Clear	4	47.63	21.16	50.80	21.18	7.87	44
LAT-14-747-1.5	1 500	Polyester	White	4	47.63	33.78	50.80	21.18	8.00	28
ELAT-33-747W-2.5	2 500	Polyester	White	3	50.00	12.00	55.00	20.00	25.00	63
LAT-31-707-1	1 000	Polyester	White	3	50.80	22.86	71.12	22.23	7.62	30
LAT-31-747W-1	1 000	Polyester	White	3	50.80	22.86	71.12	22.23	7.62	30
LAT-31-759-1	1 000	Paper	White	3	50.80	22.86	71.12	22.23	7.62	30
LAT-33-707-1	1 000	Polyester	White	3	50.80	22.86	71.12	22.23	7.62	18
LAT-33-747W-1	1 000	Polyester	White	3	50.80	22.86	71.12	22.23	7.62	18
LAT-33-759-1	1 000	Paper	White	3	50.80	22.86	71.12	22.23	7.62	18
ELAT-21-722	1 000	Polyester	Clear	3	63.00	25.00	65.00	14.50	8.50	30
ELAT-21-747-YL	1 000	Polyester	Yellow	3	63.00	25.00	65.00	14.50	8.50	30
ELAT-21-773	1 000	Metallised Polyester	Silver	3	63.00	25.00	65.00	14.50	8.50	30
LAT-21-707-1	1 000	Polyester	White	3	63.50	25.40	66.04	22.23	7.62	27
LAT-21-712-1	1 000	Polyester	Clear	3	63.50	25.40	66.04	22.23	7.62	27
LAT-21-747W-1	1 000	Polyester	White	3	63.50	25.40	66.04	22.23	7.62	27
LAT-21-747YL-1	1 000	Polyester	Yellow	3	63.50	25.40	66.04	22.23	7.62	27
LAT-21-773-1	1 000	Metallized Polyester	Silver	3	63.50	25.40	66.04	22.23	7.62	27
ELAT-34-747W-1	1 000	Polyester	White	3	64.00	34.00	66.00	20.00	8.00	21
LAT-43-707-2.5	2 500	Polyester	White	2	73.02	9.53	-	22.23	36.83	40
LAT-12-652-2.5	2 500	Polyimide	Amber	2	76.20	9.53	81.28	22.23	29.21	50
LAT-12-709-2.5	2 500	Removable Polyester	White	2	76.20	9.53	81.28	22.23	29.21	50
LAT-12-747-2.5	2 500	Polyester	White	2	76.20	9.53	81.28	22.23	29.21	50
LAT-12-747YL-2.5	2 500	Polyester	Yellow	2	76.20	9.53	81.28	22.23	29.21	50
LAT-32-747W-1	1 000	Polyester	White	2	76.20	22.86	81.28	22.23	29.21	20
LAT-32-759-1	1 000	Paper	White	2	76.20	22.86	81.28	22.23	29.21	20
LAT-34-707-1	1 000	Polyester	White	2	76.20	36.50	81.28	22.23	29.21	12
LAT-34-747W-1	1 000	Polyester	White	2	76.20	36.50	81.28	22.23	29.21	18
LAT-34-759-1	1 000	Paper	White	2	76.20	36.50	81.28	22.23	29.21	18
LAT-44-707-2.5	2 500	Polyester	White	2	91.44	9.53	-	22.23	16.51	40

Note: Labels are sorted by width, height, 3 digit material number (within reference).



Self-laminating Labels by Size

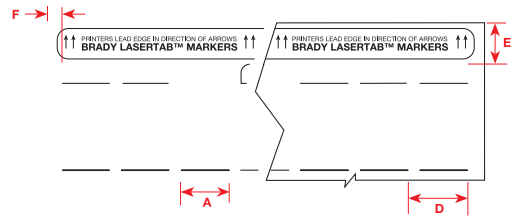

This job requires more memory than is available in this printer.

Try one or more of the following, and then print again:

For the output format, choose Optimize For Portability.

In the Device Settings page, make sure the Available PostScript Memory is accurate.

Reduce the number of fonts in the document.

Print the document in parts.