

Headers

to ASP051

Type 373 page 115

Type 374 page 116

ASP051

Spring clamp terminal block, pluggable, centerline 2.5 mm / 0.098 inches, wire entry parallel to plug direction

Technical Data

V / A / AWG 150 / 5 / 28 - 20

0.08 - 0.5 mm² 130 V / 2.5 kV / 4 A

Insulation co-ordination according to EN 60664-1

Clearance and creepage distances min. 1.7 mm

Insulating material class CTI 600

Overvoltage category III III II

Pollution degree 3 2 2

Rated voltage 80 320 320

Rated test voltage 0.8 4 2.5


Protection category according to IEC 529 IP20

Min. insul. strip length 8 mm

Pole size 2 - 12

Color green

Dimensions in mm 1 mm = 0.0394 in.

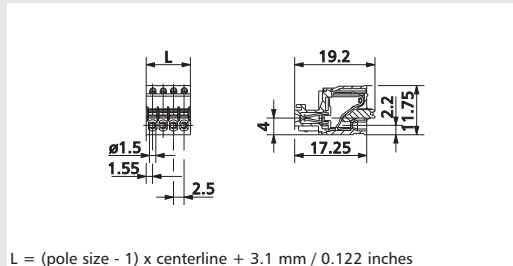

Part numbers (P/N)

(information: page 16)

Complete the part number by adding the pole size.

ASP051

centerline 2.5 mm / 0.098 inches

P/N ASP051

	02	03	04	05	06	07	08
<input type="text"/>	09	10	11	12			

- Standard pole sizes
- Available on demand. Minimum order quantity 5000 pieces per item.