

STEINEL®

Classic Heat Gun Kit Limited Edition

Special Offer



Part No. 34838

Featuring STEINEL's Most Popular
Heat Gun and Accessories:

- HL 1910 E Variable Temperature Electronic Heat Gun
- 39mm Reflector Nozzle
- 14mm Reflector Nozzle
- Overhead Hanger
- 9mm Reduction Nozzle
- Aluminum Carrying Case
- Application Hand Book

Buy Now!

Available While Supplies Last

STEINEL® Classic Quality





HL 1910 E
Variable Temperature
Electronic Heat Gun

Variable temperature: 120° F - 1100° F
3 Stage airflow: cool / 10.6 / 17.6 CFM
1500 Watts



**Electronic
Thermocouple Control**

Microprocessor measures and regulates heat produced, preventing heat back-up even with restricted airflow. Extends life of tool and enables use of specialty reduction nozzles.

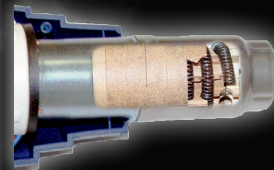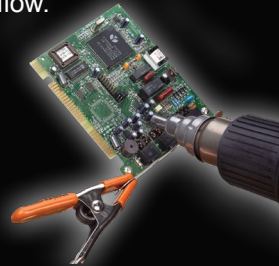

**DuraTherm™
Heating Element**

Ceramic Encapsulated Heating System is unsurpassed for even heat and long life. Coils are wound through a series of stacked ceramic disks achieving a "honey-comb" effect that fully encapsulates and supports.



Made in E.U.  