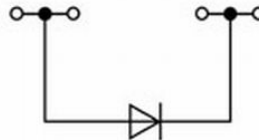
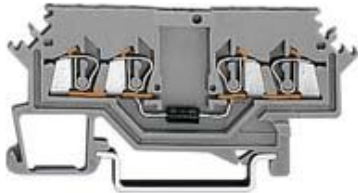

Item no.: 279-623/281-410
Product description: 4-CONDUCTOR DIODE TERMINAL BLOCK WITH DIODE
1N4007



Produkt kann von Bild abweichen / product may differ

Packing unit 100 pieces

RoHS compliant

Product group	1 (Rail Mounted Terminal Blocks)
Cross section [mm ²]	0.08 - 1.5 mm ²
Cross section [AWG]	28 - 16 AWG
Connection method	CAGE CLAMP® CONNECTION
Current intensity EN	0.5 A
Nominal voltage	250 V
Reverse voltage	1000 V
Weight	6.03 g
Color	gray
Wiring type	Front-entry
No. of connection Points	4
No. of potentials	1
Height	27 mm
Height	1.06 in
Width	4 mm
Width	0.157 in
Depth	68 mm
Depth	2.68 in
Strip length from	8 mm

Strip length to
Strip length
Mounting

9 mm
0.33 in
TS 35



Item no.	Admission office	Approval no.	Voltage [V]	Current [A]	Cross section [mm ²]
279-623/281-410	ABS	05-HG476175/3-PDA	250		1,5
279-623/281-410	BV	07436/Co	250		1,5
279-623/281-410	CCA	NL6098	250		1,5
279-623/281-410	KEMA	2105357.01	250		1,5
279-623/281-410	LR	91/20112(E6)	250		1,5
279-623/281-410	PRS	TE/1718/880590/08	250		1,5
279-623/281-410	RMR	11130002	250		1,5

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected