


VELVE OLED

Introduction OLED Module


- ✓ Full colour tunable OLED Module
- ✓ 24V DC connection
- ✓ With integrated control PCB on the backside
- ✓ Including DMX512 & DALI interface
- ✓ Uniform light distribution by integrated calibration
- ✓ Dimmable

Specification OLED Module

Model Number	52800
Active Area (W x L)	123.0mm x 123.0 mmm
Size (W x L x T)	146.4 mm x 133.4 mm x 8.7 mm
Weight	192g
Rated Current	110mA
Rated Voltage	24VDC
Power Consumption	2.6W
Color	RGB Colour Tunable
Luminous Efficacy	31lm/W
Luminance	1,000cd/m ²
Correlated Color Temperature	3,000K
Luminous Flux	47.6lm
CRI Ra	>80
CRI R9	>80
Chromaticity coordinate (white)	(0.43,040)
Operation Temperature	-20 ~ +65°C
Storage Temperature	-30 ~ +80°C
Lifetime (LT70)	8,000hrs
Lifetime (LT50)	20,000hrs
Interface	DMX512/DALI
Regulation	UL 8750
Country of Origin	Japan

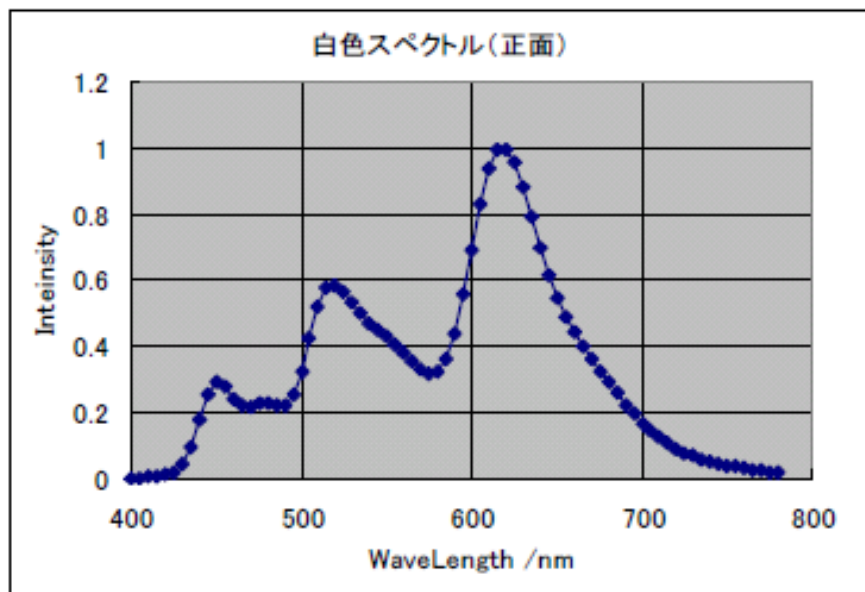


Spectral Distribution

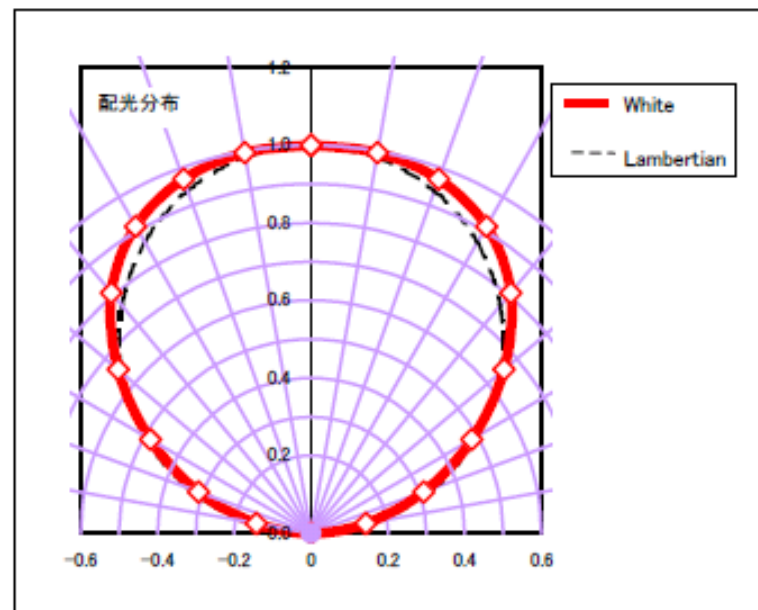

Light Distribution Curve

Colour Consistency

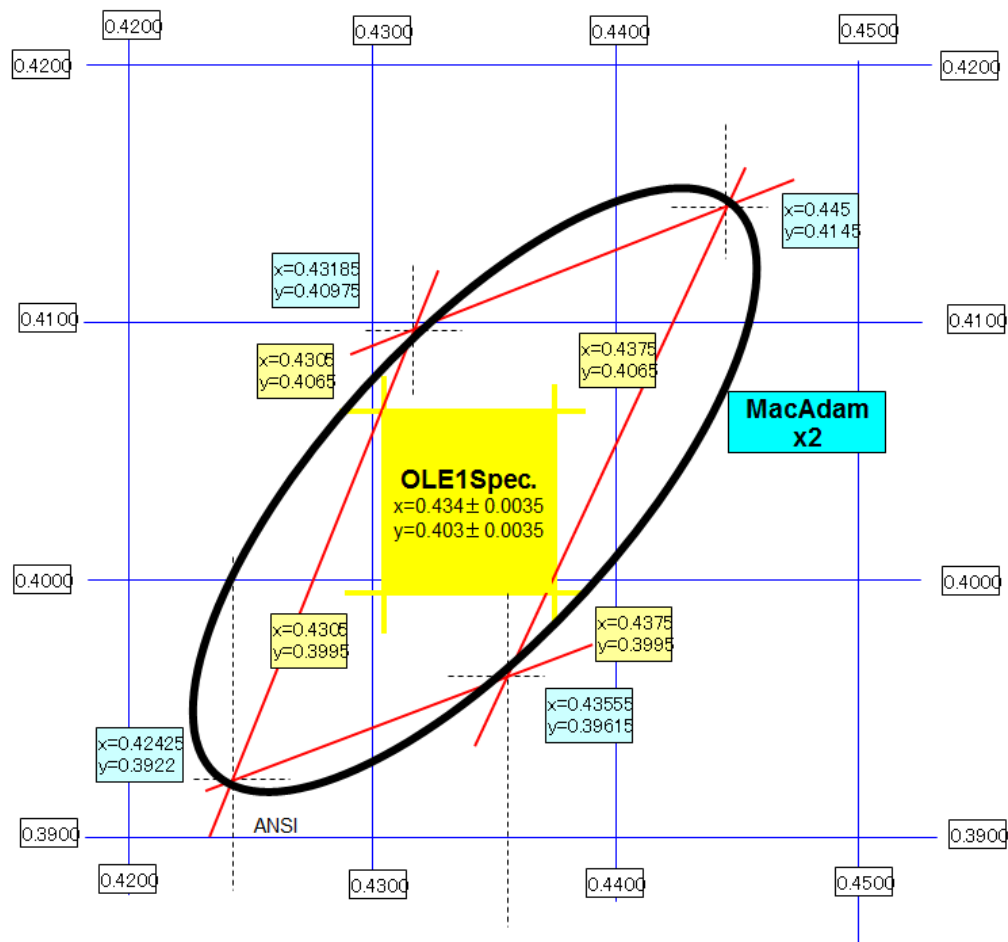

Details OLED Module

