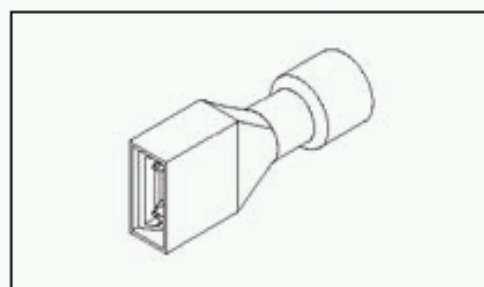



1-1838219-0 Product Details

 [Live Product Chat](#)


1-1838219-0

TE Internal Number: 1-1838219-0

 [Active](#)

Quick Disconnect Receptacles - Insulated

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Proprietary Name = EURO-CRIMP
- Receptacle Style = Straight
- Fully Insulated
- Wire Range = 0.30-1.40² [22-16] mm [AWG]
- Tab Fit = 4.80 x 0.80 mm

[View all Features](#)

 [Add to My Part List](#)
 [Request Sample](#)
 [Find Similar Products](#)
 [Buy Product](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

Documentation & Additional Information

Product Drawings:

- [EURO-CRIMP FULLY INSULATED RED FEMALE PUSH-ON TERMIN...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- [Euro-Crimp Terminals and Splices](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Proprietary Name](#) = EURO-CRIMP
- [Receptacle Style](#) = Straight
- [Tab Fit \(mm \[in\]\)](#) = 4.80 x 0.80 [.189 x .031]
- [Insulation Diameter \(mm \[in\]\)](#) = 3.56 [.140] Max.
- [Insertion Force](#) = Normal
- [Material](#) = Brass
- [Finish](#) = None
- [Dimple Type](#) = Dimple without wire stop
- Insulation Support = Insulation Support
- Color = Red
- Insulation Material = PVC

Electrical Characteristics:

- Voltage (VAC) = 600

Body Related Features:

- [Fully Insulated](#) = Yes
- [Wire Range \(mm \[AWG\]\)](#) = 0.30-1.40² [22-16]
- [Flammability Rating](#) = UL 94V-0
- Stock Thickness (mm [in]) = 0.41 [0.016]

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Loose Piece

Other:

- Brand = AMP

 [BOOKMARK](#) 

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat with Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage Your Account](#)