

Products

B4 series | Double-pole switch 16A quick connection 6.3 black body



sample image

PRODUCT CODE: B412C1100000

Wiring diagrams



Terminal type



accessories

Body colour



Actuator colour



Marking



Rating

16 (6) A / 250 VAC

10 (4) A / 250 VAC - 5E4

T120/55 °C

20 A / 125 VAC

1/3 HP - 125 VAC

16 A / 250 VAC


3/4 HP - 250VAC

T105 °C


Approvals



Dimensions (mm)

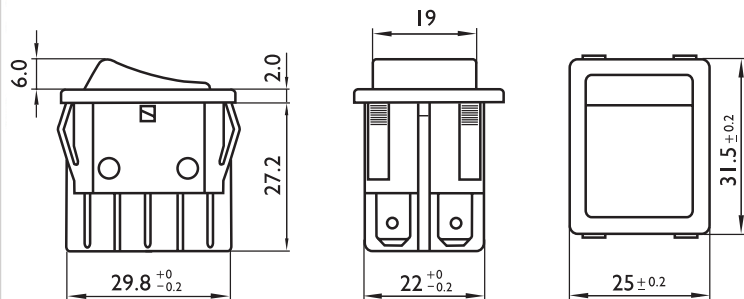

Cut out (mm)

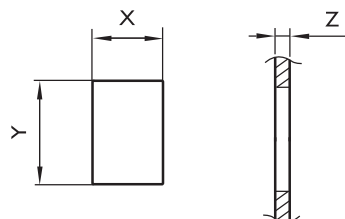

Z	Y	X
0.7-1.25	30.0 0 -0.1	22.0 +0.3 -0
1.25-2.0	30.2 0 -0.1	22.0 +0.3 -0
2.0-3.0	30.6 0 -0.3	22.0 +0.3 -0
3.0-4.0	30.8 0 -0.3	22.0 +0.3 -0

Termination

