


# Data Sheet

## Benchtop Video Generator for Computer Monitor, PC and MAC


### Model 1280B

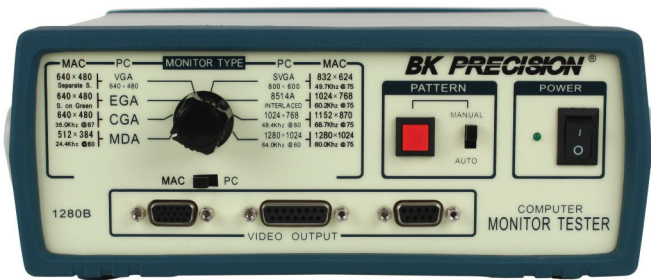

The 1280B is a fully featured benchtop design to test both Mac and PC monitors. All patterns can be manually selected or place the 1280B in Auto for automatic cycling of each available pattern. Designed to test (burn in) one to four monitors, the 1280B can also be used as a display generator. Full color, green, blue, red, black and white.

#### Features:

- PC and Mac Patterns
- 16 Monitor Types/Resolution Selections
- Color Bar, Cross Hatch, Dot, Color Raster
- VGA, SVGA, RGB, HVV & Four DB 15 (Rear panel) for multiple monitor burn in

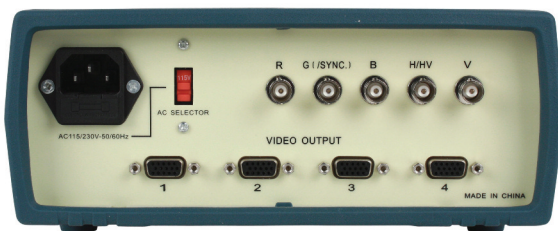

Specifications		model
		1280B
<b>Available Patterns</b>		
	Color Bars	
	Color Rasters	
	Dot	
	Crosshatch	
<b>Outputs</b>		
	RGB	
	H/HV Sync	
	V Sync	
<b>Resolutions</b>		
<b>PC</b>		
	1280 x 1024	
	1024 x 768 (non-interlaced)	
	8415A (interlaced)	
	SVGA 800 x 600	
	SVGA 1024 x 768	
	VGA 640 x 480	
	VGA 640 x 350	
	VGA 720 x 400	
	EGA	
	CGA	
	MDA	
<b>Mac</b>		
	1280 x 1024	
	1152 x 870	
	1024 X 768 (non-interlaced)	
	832 x 624	
	640 x 480	
	512 x 384	
<b>General</b>		
Power Source	9V battery or AC adapter	
Dimensions	3.125 x 9.44 x 9.25" (78 x 240 x 235mm)	
Weight	2.5lbs. (1.1kg)	
<b>One Year Warranty</b>		
Included Accessories: BE 9 AC adapter		