

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [63811-1100](#)

Status: **Active**

Description: Hand Crimper

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Application Tooling
Series	T0102
Comments	Prototype and field repair
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Product Name	N/A
Survey	www.molex.com//review/apptool_survey.html
Tool Type	Handtool

Material Info

Reference - Drawing Numbers

Application Tooling Documents

ATS-6381111HM, TM-638000029, TM-638000029CN, TM-638000029DE, TM-638000029FR, TM-638000029IT, TM-638000029JP, TM-638000029KR, TM-638000029MY, TM-638000029PL, TM-638000029RU, TM-638000029SK, TM-638000029SP, TM-638000029TH, TM-638000029TW, TM-638000029VN

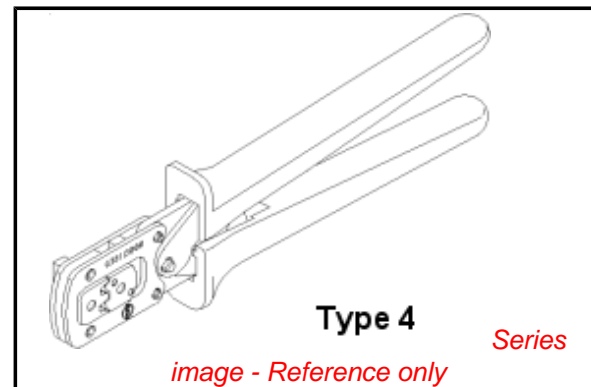

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

T0102Series

Application Tooling Description	FAQ Product #
--	----------------------

3.18mm Diameter HCS-125 Pin and Socket Crimp Terminal, Series 1901, Female, with Tin (Sn) Plated Brass Contact, 10-14 AWG, Reel	0018121601
3.18mm Diameter HCS-125 Pin and Socket Crimp Terminal, Series 1901, Female, with Tin (Sn) Plated Brass Contact, 10-14 AWG, Bag	0018121602
3.18mm Diameter HCS-125 Pin and Socket Crimp Terminal, Series	0018122601

1900, Male, with Tin
(Sn) Plated Brass
Contact, 10-14 AWG,
Reel
3.18mm Diameter 0018122602
HCS-125 Pin and
Socket Crimp
Terminal, Series
1900, Male, with Tin
(Sn) Plated Brass
Contact, 10-14 AWG,
Bag

This document was generated on 04/13/2012

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION