

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [501628-3991](#)
Status: **Active**
Description: 0.30mm Pitch Easy-On™ Type FPC Connector, 0.90mm Mated Height, Right Angle, SMT, Bottom Contact Style, 39 Circuits, Lead-Free

Documents:

3D Model	Application Specification AS-501628-001 (PDF)
Drawing (PDF)	Packaging Specification SPK-501628-001 (PDF)
Product Specification PS-501628-001 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	FFC/FPC Connectors
Series	501628
Comments	FPC with tabs
Product Name	Easy-On™

Physical

Circuits (Loaded)	39
Contact Position	Bottom
Durability (mating cycles max)	10
Entry Angle	90° Angle
Mated Height	0.90mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.30mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-25°C to +85°C
Termination Interface: Style	Surface Mount
Wire/Cable Type	FPC only


Electrical

Current - Maximum per Contact	0.2A
Voltage - Maximum	50V

Material Info

Reference - Drawing Numbers

Application Specification	AS-501628-001
Packaging Specification	SPK-501628-001
Product Specification	PS-501628-001, RPS-501628-002, RPS-501628-003, RPS-501628-004
Sales Drawing	SD-501628-001, SD-501628-003

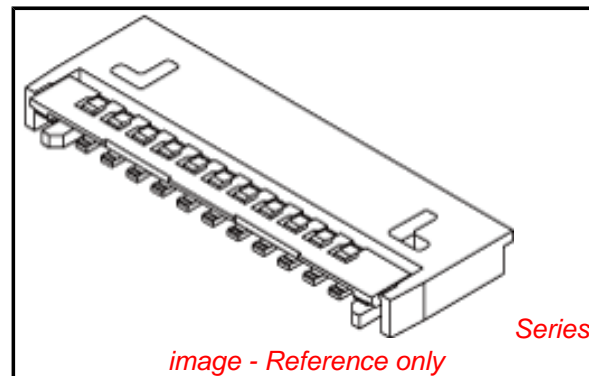

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[501628Series](#)