



TORX® Bits


The ideal multi-purpose bits for all around quality and performance

Made in Germany - Production Quality

Impact resistant modified chrome-vanadium-molybdenum, tool steel, hardened

Suitable for all applications
Hardness HRC 59-61
Suitable for both manual & machine applications

High resistant to wear and tear for a long tool life

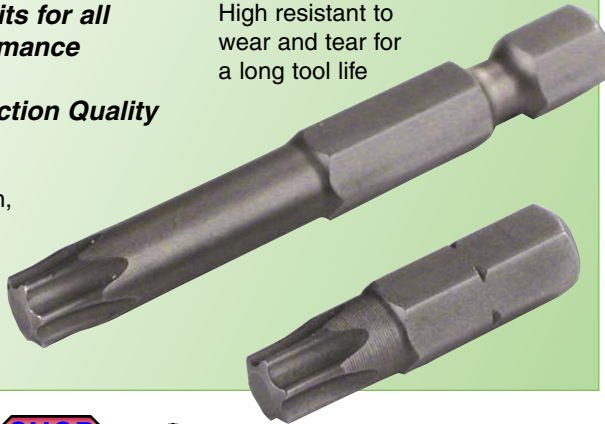

715 TORX® Bits, 1/4"

Item No.	Size	mm	pkg.	lbs.
715 05	T5	25	10	.12
715 06	T6	25	10	.12
715 07	T7	25	10	.12
715 08	T8	25	10	.12
715 09	T9	25	10	.12
715 10	T10	25	10	.12
715 15	T15	25	10	.12
715 20	T20	25	10	.12
715 25	T25	25	10	.12
715 27	T27	25	10	.13
715 30	T30	25	10	.14
715 40	T40	25	10	.15



745 TORX® Power Bits, 1/4" Hex Drive, Length 2.0"/50mm

Item No.	Size	mm	pkg.	lbs.
745 11	T6	50	10	.18
745 12	T7	50	10	.18
745 13	T8	50	10	.18
745 17	T9	50	10	.18
745 19	T10	50	10	.18
745 21	T15	50	10	.18
745 23	T20	50	10	.18
745 29	T25	50	10	.18
745 31	T27	50	10	.18
745 33	T30	50	10	.18
745 35	T40	50	10	.18



745 TORX® Power Bits, 1/4" Hex Drive, Length 3.5"/90mm

Item No.	Size	mm	pkg.	lbs.
745 63	T6	90	10	.03
745 65	T7	90	10	.03
745 67	T8	90	10	.03
745 69	T9	90	10	.03
745 71	T10	90	10	.03
745 73	T15	90	10	.03
745 75	T20	90	10	.04
745 77	T25	90	10	.04
745 79	T27	90	10	.04
745 81	T30	90	10	.04
745 83	T40	90	10	.04



745 TORX® Power Bits, 1/4" Hex Drive, Length 6.0"/152mm

Item No.	Size	mm	pkg.	lbs.
745 86	T10	152	10	.04
745 87	T15	152	10	.04
745 88	T20	152	10	.04
745 89	T25	152	10	.04
745 90	T27	152	10	.04
745 91	T30	152	10	.04



725 TORX® Bits, 5/16"

Item No.	Size	mm	pkg.	lbs.
725 25	T25	35	10	.27
725 27	T27	35	10	.27
725 30	T30	35	10	.27
725 40	T40	35	10	.28
725 45	T45	35	10	.31
725 50	T50	35	10	.32
725 55	T55	35	10	.52



745 TORX® Power Bits, 1/4" Hex Drive, Length 2.75"/70mm

Item No.	Size	mm	pkg.	lbs.
745 36	T6	70	1	.02
745 38	T7	70	1	.02
745 42	T8	70	1	.02
745 44	T9	70	1	.02
745 46	T10	70	1	.02
745 48	T15	70	1	.02
745 51	T20	70	1	.03
745 53	T25	70	1	.03
745 56	T27	70	1	.04
745 58	T30	70	1	.04
745 61	T40	70	1	.04

Wiha TORX® Bit Packs



715 TORX® Insert Bit Packs, 1" CVM S2 modified tool steel.

Item No.	Size	mm	lbs.	2 Bit Pack
715 50	T5	25	.03	
715 51	T6	25	.03	
715 52	T7	25	.03	
715 53	T8	25	.03	
715 54	T9	25	.03	
715 55	T10	25	.03	
715 56	T15	25	.03	
715 57	T20	25	.03	
715 58	T25	25	.03	
715 59	T27	25	.04	
715 60	T30	25	.04	
715 61	T40	25	.04	



725 TORX® Insert Bit Packs, 5/16"

CVM S2 modified tool steel.

Item No.	Size	mm	lbs.	2 Bit Pack
725 31	T30	35	.28	
725 41	T40	35	.28	
725 46	T45	35	.31	
725 51	T50	35	.32	
725 56	T55	35	.52	