

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [43640-0601](#)
Status: **Active**
Overview: [Micro-Fit 3.0™ Connectors](#)
Description: 3.00mm Pitch Micro-Fit 3.0™ Plug Housing, Single Row, without Panel Mount Ears, 6 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-43650 \(PDF\)](#)
[Test Summary TS-43045-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)
[Product Literature \(PDF\)](#)

Agency Certification

CSA	LR19980
TUV	R72081037
UL	E29179

General

Product Family	Crimp Housings
Series	43640
Application	Power, Wire-to-Wire
Comments	Glow Wire Equivalent Part Number 436400609
MolexKits	Yes
Overview	Micro-Fit 3.0™ Connectors
Product Literature Order No	987650-5984
Product Name	Micro-Fit 3.0™

Physical

Circuits (maximum)	6
Color - Resin	Black
Flammability	94V-0
Gender	Male
Glow-Wire Compliant	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Polyester
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.00mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Electrical

Current - Maximum per Contact	5A
-------------------------------	----

Material Info

UPC	800754950923
-----	--------------

Reference - Drawing Numbers

Product Specification	PS-43650
Sales Drawing	SD-43640-****
Test Summary	TS-43045-001

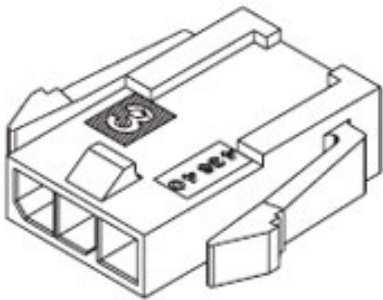


image - Reference only

Series

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[43640Series](#)

Mates With
Micro-Fit 3.0™ Receptacle Housing [43645](#)

Use With
Micro-Fit 3.0™ Crimp Terminal [43031](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION