

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [03-09-2062](#)
Status: **Active**
Overview: [Standard .093"](#)
Description: 2.36mm Diameter Standard .093" Pin and Socket Plug Housing, 6 Circuits, Dual Row

Documents:
[3D Model](#) [Product Specification PS-43660-9999 \(PDF\)](#)
[Drawing \(PDF\)](#) [Packaging Specification PK-1261-001 \(PDF\)](#)
[Product Specification PS-02-09 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series [1261](#)
Application Power, Wire-to-Wire
Comments 14.0A max. can be achieved when housing is used with 42477 or 42478 terminals

Overview [Standard .093"](#)
Product Name Standard .093"

Physical

Circuits (maximum) 6
Color - Resin Natural
Flammability 94V-2
Gender Dual
Glow-Wire Compliant No
Material - Resin Nylon
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 5.03mm
Stackable No
Temperature Range - Operating -40°C to +105°C

Electrical


Current - Maximum per Contact 11A

Material Info

Old Part Number 1261-P1

Reference - Drawing Numbers

[Packaging Specification](#) PK-1261-001
[Product Specification](#) PS-02-09, PS-43660-9999
[Sales Drawing](#) SD-1261-*

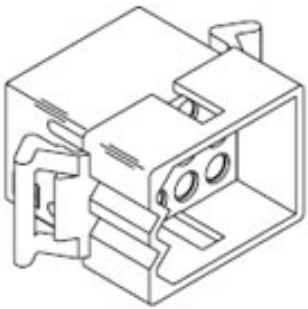

Series

image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[1261Series](#)

Mates With
[1261r](#)

Use With
[1189](#) Crimp Terminals, [1190](#) Crimp Terminals, [1380](#) Male Crimp Terminals, [1381](#) Female Crimp Terminals, [1433](#) Crimp Terminals, [1434](#) Male Crimp Terminals, [1973](#) , [2151](#) , [2273](#) , [2870](#) , [2871](#) , [4272](#) , [4550](#) , [6271](#)