

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [09-50-7101](#)
Status: **Active**
Overview: [KK® Interconnection System](#)
Description: 3.96mm Pitch KK® Crimp Terminal Housing, 10 Circuits

Documents:

3D Model	Packaging Specification PK-2139-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-08-50 (PDF)	

Agency Certification

UL	E29179
----	--------

General

Product Family	Crimp Housings
Series	2139
Application	Power, Wire-to-Board
MolexKits	Yes
Overview	KK® Interconnection System
Product Name	KK®

Physical

Circuits (maximum)	10
Color - Resin	Natural
Flammability	94V-2
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Nylon
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm
Temperature Range - Operating	0°C to +75°C

Material Info

Old Part Number	2139-10C
UPC	800753640795

Reference - Drawing Numbers

Packaging Specification	PK-2139-001
Product Specification	PS-08-50
Sales Drawing	SD-2139

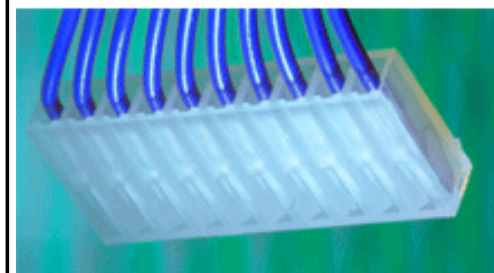


image - Reference only

Series

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Contains SVHC: No**
**Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[2139Series](#)

Use With

[2478](#) Crimp Terminals for 18-24 AWG, [2578](#)
 Crimp Terminals for 22-26 AWG

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION