

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [35922-9002](#)
Status: **Active**
Overview: [MV-396™](#)
Description: 3.96mm Pitch Wire-to-Board Terminal

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification PK-35922-001 \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	35922
Application	Power
Crimp Quality Equipment	Yes
Overview	MV-396™
Product Name	MV-396™


Physical

Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Packaging Type	Reel
Plating min - Mating	1.524µm
Plating min - Termination	1.524µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.00mm max.
Wire Size AWG	18, 20
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35922-001
Sales Drawing	SD-35922-500

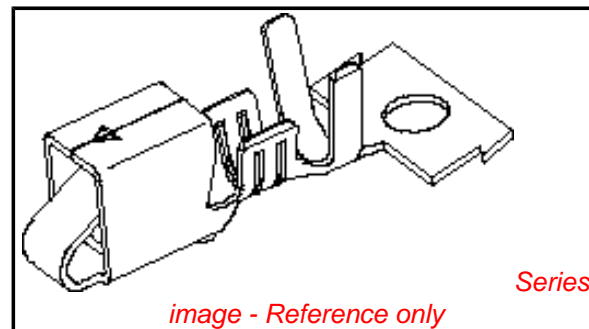

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

**Contains SVHC: No
Low-Halogen Status
Low-Halogen**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[35922Series](#)

Use With

[35977](#)

Application Tooling | FAQ

*Tooling specifications and manuals are
 found by selecting the products below.
 Crimp Height Specifications are then
 contained in the Application Tooling
 Specification document.*

Global

Description	Product #
Hand Crimp Tool for Wire-to-Board Crimp Terminals	0638235900
T2 Terminator Die	0638557000
FineAdjust™	0638657000
Applicator	