

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [51047-0700](#)
Status: **Active**
Overview: [PicoBlade™](#)
Description: 1.25mm Pitch PicoBlade™ Wire-to-Wire Plug Housing, 7 Circuits

Documents:

[3D Model](#) [Product Specification PS-51021-009 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Housings
Series	51047
Application	Signal, Wire-to-Wire
Overview	PicoBlade™
Product Name	PicoBlade™

Physical


Circuits (maximum)	7
Color - Resin	Natural
Gender	Male
Glow-Wire Compliant	No
Lock to Mating Part	Yes
Material - Resin	Polyester
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Stackable	No
Temperature Range - Operating	-40°C to +85°C

Material Info

UPC 800754382786

Reference - Drawing Numbers

Product Specification [PS-51021-009](#), [RPS-51021-033](#), [RPS-51047-001](#)
 Sales Drawing [SD-51047-**00](#)

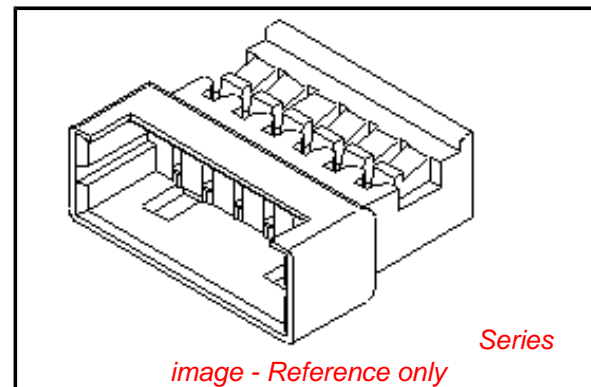

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[51047Series](#)

Mates With

[51021](#) housing

Use With

[50125](#) Crimp Terminal, [50133](#) Crimp Terminal