

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

22-55-2062

Status:

Active

Overview:

C-Grid® Products

Description:

2.54mm Pitch SL™ Crimp Housing, Dual Row, Version B, Polarized, 6 Circuits

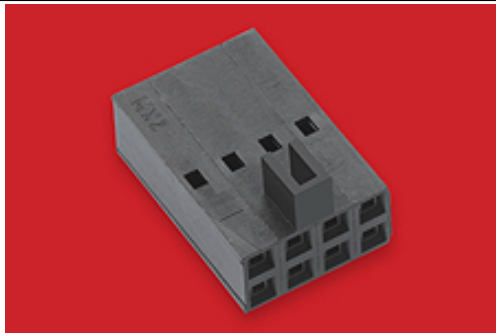


image - Reference onlySeries

Documents:

3D Model

Drawing (PDF)

Product Specification PS-70058 (PDF)

Product Specification PS-70400 (PDF)

Test Summary TS-70058-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

UL

LR19980

E29179

General

Product Family

Series

Application

Comments

Overview

Product Name

Crimp Housings

70450

Signal, Wire-to-Board

Version B

C-Grid® Products

SL™

Physical

Breakaway

Circuits (maximum)

Color - Resin

Flammability

Gender

Glow-Wire Compliant

Material - Resin

Number of Rows

Packaging Type

Panel Mount

Pitch - Mating Interface

Stackable

Temperature Range - Operating

No

6

Black

94V-0

Female

No

Polyester

2

Bag

No

2.54mm

No

-40°C to +105°C

Material Info

Old Part Number

UPC

70450-0051

800753626485

Reference - Drawing Numbers

Product Specification

Sales Drawing

Test Summary

PS-70058, PS-70400

SD-70450-0050-0075

TS-70058-001

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

70450Series

Mates With

70246 Straight Header, 70247 Right Angle Header, 87256, 87257

Use With

70058 , 71851

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION