

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [35464-8000](#)
Status: **Active**
Overview: Bulb Sockets
Description: Positive Terminal for PT Bulb Socket, AVSS 0.50~0.85mm²

Documents:

Drawing (PDF) Packaging Specification PK-35464-8000 (PDF)
Product Specification PS-35842-001 (PDF) RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Terminals
Series	35464
Application	Power
Crimp Quality Equipment	Yes
Overview	<u>Bulb Sockets</u>
Product Name	Bulb Socket


Physical

Gender	Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Unplated
Material - Plating Termination	Unplated
Packaging Type	Reel
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.90mm max.
Wire Size AWG	18, 20
Wire Size mm ²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35464-8000
Product Specification	PS-35842-001
Sales Drawing	SD-35464-001

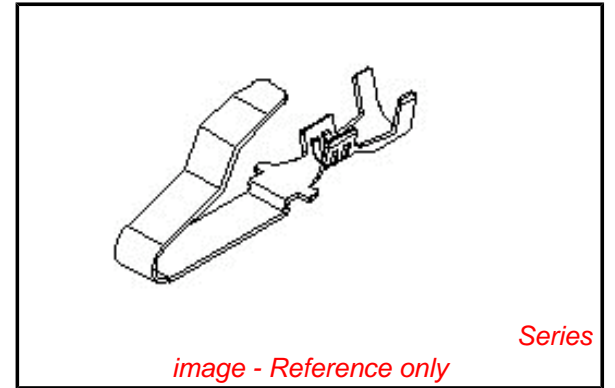

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

35464Series

Use With

35842 , 35843

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
FineAdjust™	0639012100
Applicator for Sealed PT-Bulb Socket Positive Terminal 0.50-0.85mm ² and 18-20 AWG.	
Hand Crimp Tool for Bulb Socket Positive Terminal	0638195000
Manual Extraction Tool	0638131500

This document was generated on 04/02/2012

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION