

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [22-55-2541](#)
Status: **Active**
Overview: [C-Grid® Products](#)
Description: 2.54mm Pitch SL™ Crimp Housing, Dual Row, Version A, Non-polarized, 54 Circuits

Documents:

3D Model	Product Specification PS-70400 (PDF)
Drawing (PDF)	Test Summary TS-70058-001 (PDF)
Product Specification PS-70058 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA LR19980

General

Product Family	Crimp Housings
Series	70450
Application	Signal, Wire-to-Board
Comments	Version A
Overview	C-Grid® Products
Product Name	SL™

Physical

Breakaway	No
Circuits (maximum)	54
Color - Resin	Black
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Polyester
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40°C to +105°C

Material Info

Old Part Number	70450-0026
UPC	800753778788

Reference - Drawing Numbers

Product Specification	PS-70058, PS-70400
Sales Drawing	SD-70450-0001-0026
Test Summary	TS-70058-001

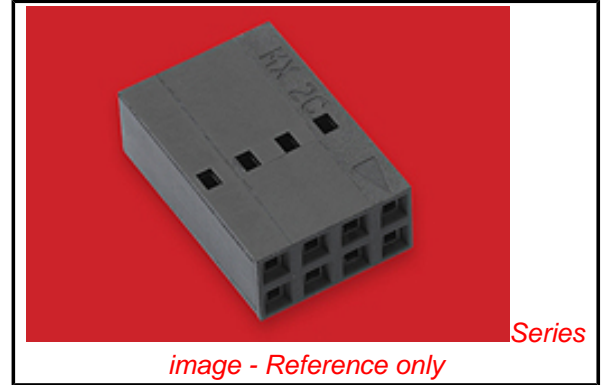


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[70450Series](#)

Mates With

[8624](#) , [70203](#) , [70029](#) , [70567](#) , [70568](#) ,
[71308](#) , [71349](#) , [70287](#) , [70227](#) , [70280](#) ,
[70260](#) , [8723](#) , [8724](#) , [70204](#)

Use With

[70058](#) , [71851](#)