

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

22-55-2122

Status:


Active

Overview:

C-Grid® Products

Description:

2.54mm Pitch SL™ Crimp Housing, Dual Row, Version B, Polarized, 12 Circuits

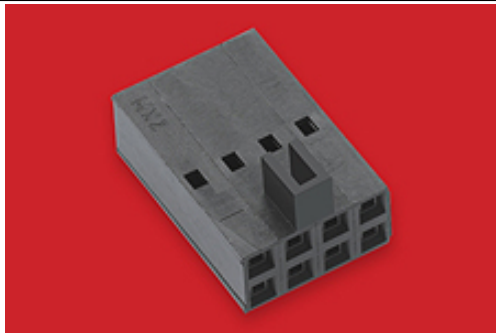

Series

image - Reference only

Documents:

- | | |
|--|--|
| 3D Model | Product Specification PS-70400 (PDF) |
| Drawing (PDF) | Test Summary TS-70058-001 (PDF) |
| Product Specification PS-70058 (PDF) | RoHS Certificate of Compliance (PDF) |

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	70450
Application	Signal, Wire-to-Board
Comments	Version B
Overview	C-Grid® Products
Product Name	SL™

Physical

Breakaway	No
Circuits (maximum)	12
Color - Resin	Black
Flammability	94V-0
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Polyester
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Old Part Number	70450-0054
UPC	800754396585

Reference - Drawing Numbers

Product Specification	PS-70058, PS-70400
Sales Drawing	SD-70450-0050-0075
Test Summary	TS-70058-001

EU RoHS

ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

70450Series

Mates With

70246 Straight Header, 70247 Right Angle Header, 87256, 87257

Use With

70058 , 71851

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION