

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19432-0014](#)
Status: **Active**
Overview: MX150L™ Sealed Connector System
Description: MX150L™ 2 Circuit Female Sealed Receptacle for 8 AWG Wire

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#) [Product Literature \(PDF\)](#)
[Product Specification PS-19432-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E152602

General

Product Family Crimp Housings
 Series [19432](#)
 Application Power, Wire-to-Wire
 Comments Mat Seal Color is Red, Polarized to Mating Part
 Overview [MX150L™ Sealed Connector System](#)
 Product Literature Order No 987650-2181
 Product Name MX150L™

Physical

Circuits (maximum) 2
 Circuits Detail 1x1
 Flammability 94V-0
 Gender Female
 Glow-Wire Compliant No
 Keying to Mating Part N/A
 Lock to Mating Part Yes
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 5.84mm
 Polarized to Mating Part Yes
 Stackable No
 Temperature Range - Operating -40°C to +125°C

Electrical

Current - Maximum per Contact 40A

Material Info

UPC 822350191517

Reference - Drawing Numbers

Product Specification PS-19432-001
 Sales Drawing SD-19432-001

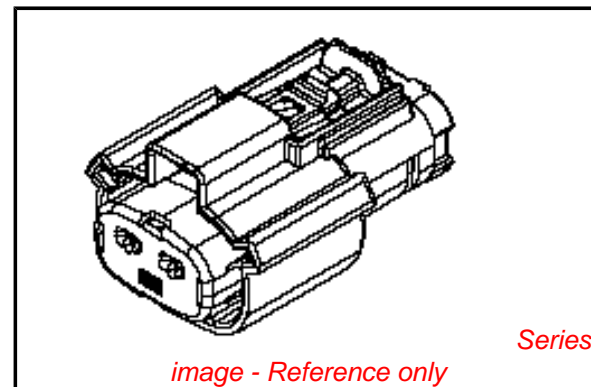


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[19432Series](#)

Mates With

[194330014 Male Plug](#)

Use With

[19434 Female Terminals](#)