

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19434-0003

Status:

Active

Overview:

MX150L™ Sealed Connector System

Description:

MX150L™ Female Terminal for 10-12 AWG Wire

Documents:

Drawing (PDF)

Product Specification PS-19432-001 (PDF)

RoHS Certificate of Compliance (PDF)

Product Literature (PDF)

Agency Certification

CSA

UL

LR18689

E152602

General

Product Family

Series

Application

Comments

Crimp Quality Equipment

Overview

Product Literature Order No

Product Name

Crimp Terminals

19434

Power

UL EI52602

Yes

MX150L™ Sealed Connector System

987650-2181

MX150L™

Physical

Gender

Material - Metal

Material - Plating Mating

Packaging Type

Wire Insulation Diameter

Wire Size AWG

Wire Size mm²

Female

Copper

Tin

Bag

3.94mm-4.45mm

10, 12

N/A

Material Info

UPC

822350193153

Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-19432-001

SD-19434-001

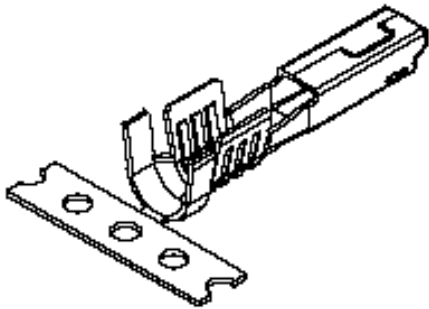


image - Reference only

Series

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19434Series

Mates With

19431 Male Terminal

Use With

19432 Female Receptacle

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

Hand Crimp Tool for 0638115300

Crimp Terminals