

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [70107-0050](#)
Status: **Active**
Overview: [C-Grid® Products](#)
Description: 2.54mm Pitch SL™ Wire-to-Wire Panel Mount Crimp Housing, Single Row, Version B, with Mounting Ears, 16 Circuits

Documents:

[3D Model](#) [Product Specification PS-70400 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	LR19980
TUV	R72081037
UL	E29179

General

Product Family	Crimp Housings
Series	70107
Application	Signal, Wire-to-Wire
Overview	C-Grid® Products
Product Name	SL™

Physical


Circuits (maximum)	16
Color - Resin	Black
Flammability	94V-0
Gender	Male
Glow-Wire Compliant	No
Material - Resin	Polyester
Number of Rows	1
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	2.54mm
Temperature Range - Operating	-40°C to +120°C

Material Info

UPC	800755031188
-----	--------------

Reference - Drawing Numbers

Product Specification	PS-70400
Sales Drawing	SD-70107-0036-0059

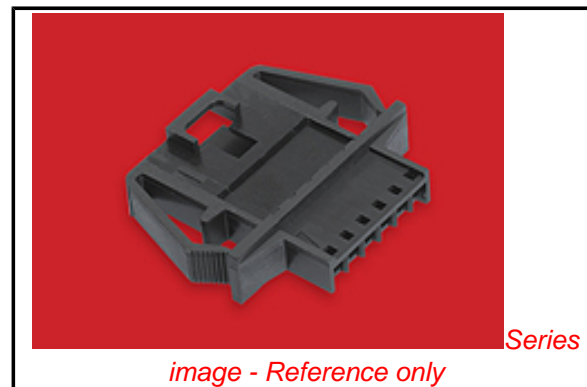

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Reviewed**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[70107Series](#)

Mates With

[70400G](#) ,, [70066g Housing](#), [70430g Receptacle](#)

Use With

[70021](#)