

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19199-0010](#)
Status: **Active**
Description: Avikrimp™ Window Butt Connector for 14-16 AWG Wire, Mylar Tape Carrier

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-015 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Splices
Series	19199
Comments	Mil Spec M7928/5-4
Crimp Quality Equipment	Yes
Mil-Spec	M7928/5-4
Product Name	Avikrimp™, Butt - Window

Physical

Barrel Type	Closed
Insulation	Nylon (PA)
Material - Metal	Copper
Packaging Type	Adhesive Tape on Reel
Temperature Range - Operating	-55°C to +105°C
Wire Insulation Diameter	4.34mm
Wire Size AWG	14, 16
Wire Size mm²	1.00 - 2.50

Electrical

Voltage - Maximum	300V
-------------------	------

Material Info

Old Part Number	WB-841T
UPC	800753046832

Reference - Drawing Numbers

Product Specification	PS-19902-011, PS-19902-015
Sales Drawing	SD-19199-003

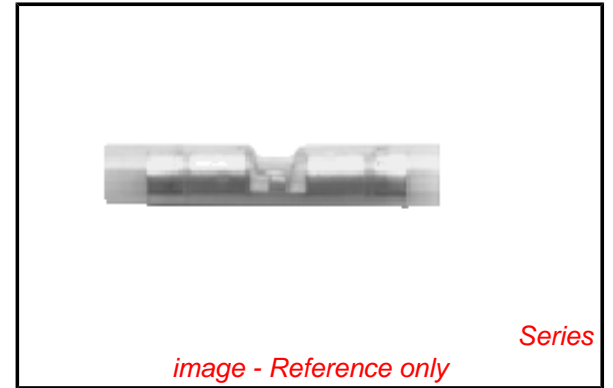


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

19199Series

Application Tooling | FAQ

*Tooling specifications and manuals are
 found by selecting the products below.
 Crimp Height Specifications are then
 contained in the Application Tooling
 Specification document.*

Global

Description

Product #

Crimp Dies for MTA-100 Tape Applicator used in 3BF Press, MTA-105 Tape Applicator used in TM-2000™ Press, and ATP-301 Air Crimping Press for Mylar Tape Mounted Terminals	0192880118
--	----------------------------

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION