



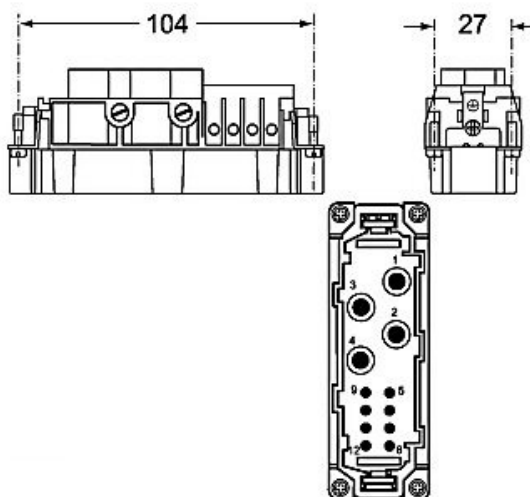

Part Number: CXM 4/8

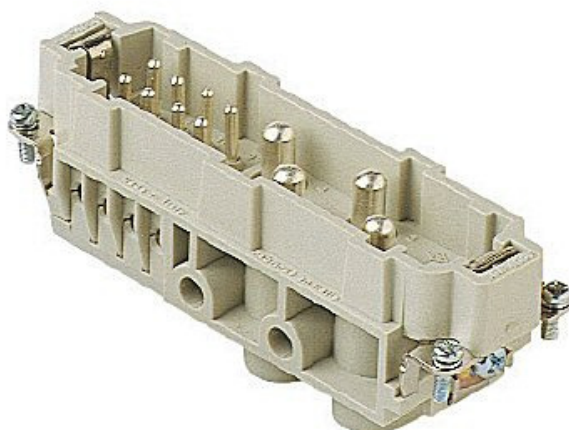

Family	inserts
Version	screw terminal connections
Series	CX
Product type	with male contacts
Model	male insert
Reference standard	EN 61984 (2001-11)
Contact type	silver plated
No. of poles	4 poles + 
Auxiliaries poles	8 poles (16A max - 230/400V/4kV/3)
Voltage (V)	400V
Current (A)	80A (A.C./D.C.)
Wire section	4mm ² - 16mm ²
Awg size	12 - 6
Quality mark	
IP degree of protection	IP20 degree of protection without enclosure; IP65, IP66, IP67, IP68 (EN 60529) and IP69K (DIN 40050 - 9) with enclosure
Fixing centre distance	size "104.27"
Impulse withstand voltage	6kV
Pollution degree	3
Barcode EAN13	8015747042635
Notes	CX 4/8 inserts:

- characteristics according to EN 61984:
 (80A 400V 6kV 3)
 (80A 400/690V 6kV 2)
 8 Auxiliary contacts: (16A 230/400V 4kV 3)
 8 Auxiliary contacts: (16A 400V 4kV 2)
- for maximum current load, see the insert load curve section
- inserts for applications with temperatures up to 180 °C, available on request

The information and the dimensions contained are not binding and may be changed without prior notice.

The drawing's dimensions are in mm.