


## WAGO - 231-532/001-000/RN01-0000. - Terminal Block

Item no.: 231-532/001-000

Product description: Header right angle solder pin, 1x1mm / 0.039x0.039in 2 pole pin spacing 2.08mm / 0.2in mating direction parallel to PCB with closed end.

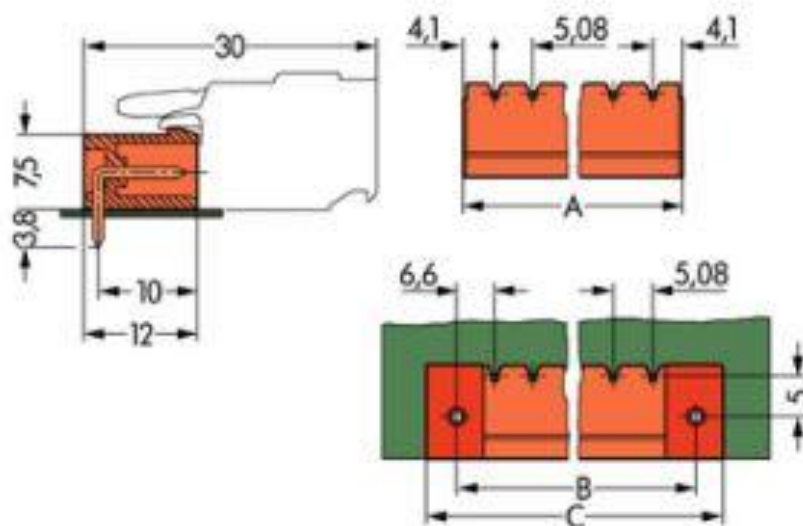

Product group	3 (Multi Conn. System)
Weight	0.848 g
Color	orange
pole count	2
Height	8.4 mm
Height	0.331 in
Width	13.36 mm
Width	0.526 in
Depth	12 mm
Depth	0.472 in
Pin spacing from	5.08 mm
Pin spacing from	0.2 in
Pollution degree	2
Measured voltage EN	320 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Pollution degree	2
Measured voltage EN	630 V
Measured shock voltage	4 kV
Current intensity EN	16 A
Material group	I
Contact material	Electrolytic copper (Ecu)
Contact surface	tin-plated